

## RS Pro Datasheet – Fiche Technique – Datenblatt


RS Pro: 144-8594




VALUE USB 2.0 Cable, A - A, M/M, 4.5 m

VALUE Câble USB 2.0 Type A-A, 4.5m

VALUE USB 2.0 Kabel, Typ A-A, 4,5m

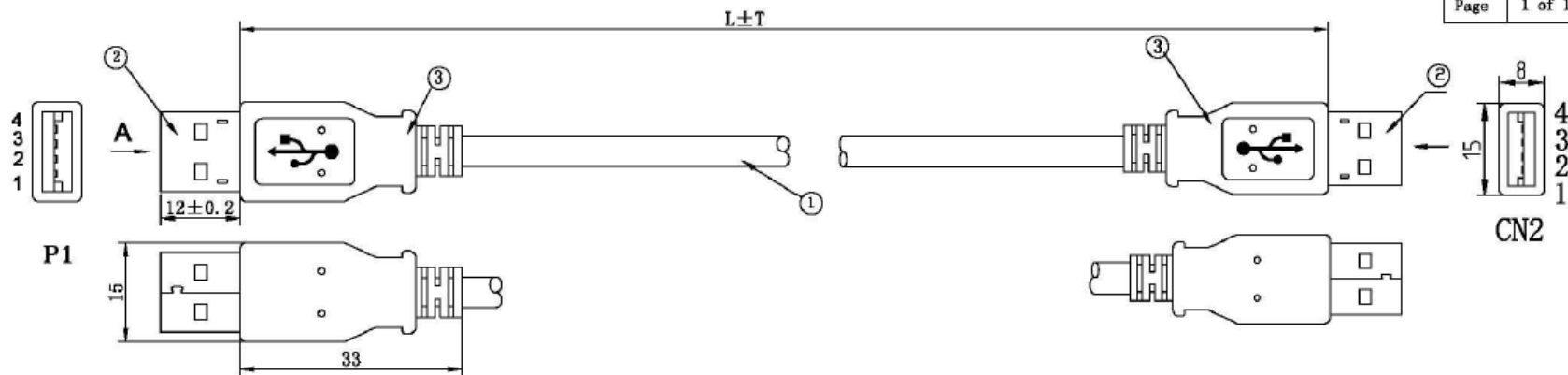

PIN OUT

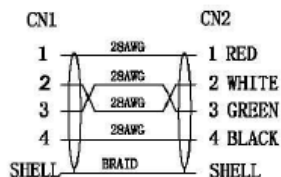

NOTE 1:

| ITEM NO.    | LENGTH     |
|-------------|------------|
| 11.99.8909R | 800±20mm   |
| 11.99.8919R | 1800±30mm  |
| 11.99.8931R | 3000±50mm  |
| 11.99.8944R | 4500±100mm |

NOTE:

- Electrical test:
    - 100% open short & miss wire test;
    - Insulation resistance:DC 300V 10M Ω ;
    - Contact resistance:3Ω Max;
    - Dielectric strength:100V AC/Minute, 1mA.
  - RoHS compliant.
  - PRINTING:USB 2.0 CABLE, 28AWG×1P+28AWG×2C
  - Packing: 1PCS/PE BAG + LABEL 100PCS/CARTON
- 11.99.8909 50PCS/CARTON

MATERIAL LIST:

| ③   | OUTER MOLD | Shore 88A PVC(UL94V-2) Color: White  | 2     |        |
|-----|------------|--|-------|--------|
| ②   | USB A TYPE | USB A /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating                                   | 2     |        |
| ①   | CABLE      | USB 2.0 28AWG(7/0.12BC*1P)+28AWG(7/0.12BC*2C)+AB B=0.12/3*16 AL-MG JACKET:PVC/WHITE (WH11) OD: 3.8±0.2mm | 1     |        |
| NO. | PARTS NAME | SPECIFICATION STANDARD   | QT' Y | REMARK |

|          |      |          |            |            |
|----------|------|----------|------------|------------|
| CUSTOMER | REF. | ITEM NO. | 11.99.8909 | 11.99.8919 |
|          |      |          | 11.99.8931 | 11.99.8944 |

|    |     |                               |            |      |              |               |          |  |            |    |
|----|-----|-------------------------------|------------|------|--------------|---------------|----------|--|------------|----|
|    |     |                               |            |      | PRODUCT NAME | USB 2.0 AM/AM | DRAW NO. |  | UNIT       | MM |
|    |     | NEW                           | 2009-11-20 | A    | DRAWNBY      | CHECKBY       | APPOBY   |  | DATE       |    |
| BY | CHK | REVISION RECORD MODIFICATIONS |            | DATE | REV.         | chenhuan      | chenhuan |  | 2009-11-20 |    |