



Tech Cases





TECH CASES

- 9" Technicians case with foam insert
240 x 325 x 112mm
- 16.5" Technicians case with foam insert
325 x 420 x 175mm
- 18" Technicians case with foam insert
360 x 465 x 175mm
- 20.5" Technicians case with foam insert
430 x 570 x 220mm



- IP67 Rated

- Completely dust tight


- Water tight to 1m
Submersion



788-7236

9" TECHNICIANS CASE WITH FOAM INSERT

- 9" IP Rated Technicians case with foam insert
- 112 x 325 x 240mm
- IP67 Rated
- Completely dust tight
- Water tight to 1m Submersion

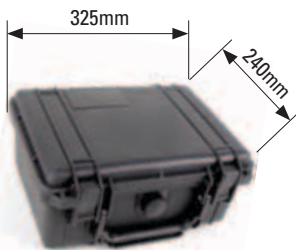


CODE NO	HxWxD / mm	kg
788-7236	112 x 325 x 240	0.765



788-7239

16.5" TECHNICIANS CASE WITH FOAM INSERT

- 16.5" IP Rated Technicians case with foam insert
- 175 x 420 x 325mm
- IP67 Rated
- Completely dust tight
- Water tight to 1m Submersion

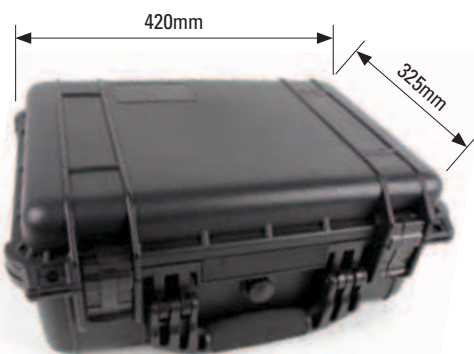


CODE NO	HxWxD / mm	kg
788-7239	175 x 420 x 325	2.69



788-7233

18" TECHNICIANS CASE WITH FOAM INSERT

- 18" IP Rated Technicians case with foam insert
- 175 x 465 x 360mm
- IP67 Rated
- Completely dust tight
- Water tight to 1m Submersion

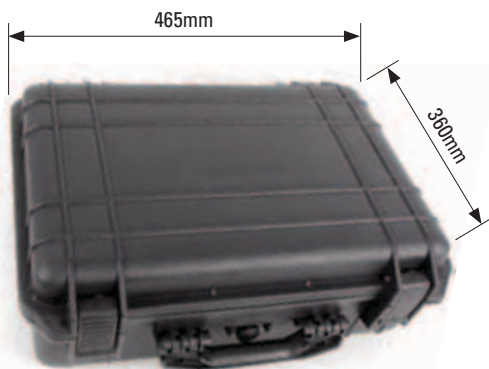


CODE NO	HxWxD / mm	kg
788-7233	175 x 465 x 360	2.90



788-7242

20.5" TECHNICIANS CASE WITH FOAM INSERT

- 20.5" IP Rated Technicians case with foam insert
- 220 x 570 x 430mm
- IP67 Rated
- Completely dust tight
- Water tight to 1m Submersion

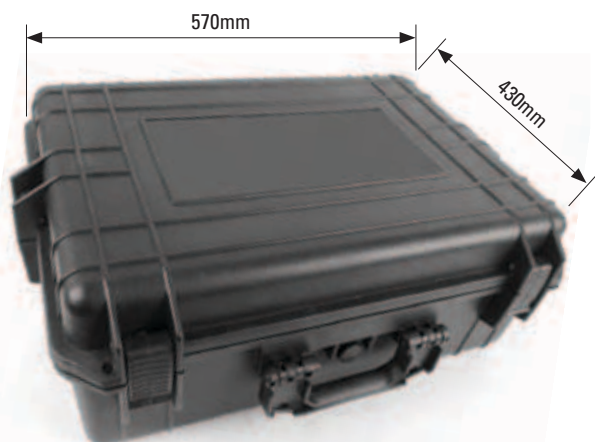

CODE NO	HxWxD / mm	kg
788-7242	220 x 570 x 430	5.11

