


Connection Plates

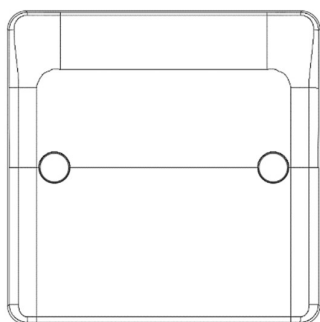

Description

This uniquely shaped range is easy to install, with clear bold terminal markings and is supplied in individual protective polybags suitable for display.

Features

- Contemporary designed profile
- Only one size 4mm screwdriver needed
- Terminals have clear bold markings
- Dual terminals of live, neutral and earth
- Large terminal capacity
- 25-year guarantee

Range

1 gang blank plate	VP1200
2 gang blank plate	VP1201
25A flex connection plate (no flex)	VP1216

Technical Specification

Voltage rating	250Vac
Current Rating	25A
Front plate material	Urea formaldehyde

Urea flammability classification UL94 grade V-0

No user serviceable parts

Back Boxes

Minimum recommended depth

	Flush 25	Dry lining 35mm	Surface 25mm
1g	DB162	DB2540	VP1221

Standards

- BS 5733+A1

Terminal Capacity

	2.5mm ²	4mm ²	6mm ²	10mm ²
L & N	5	3	2	1