





## LED PL Glass TC-TEL GX24q 4P 6W (18W) 800lm 830 AC

Article number: 146754

BAI LED PL Glass GX24q 4-pins TC-TEL 6W (18W) 3000K Frosted 800lm 230V-240V 360° 49x120mm  
Temp. -20°C +40°C LED-lamp Alt PLT Dulux T/E

The LED PL Glass GX24 (4-pin) TC-TEL lamps are replacements for the often used compact fluorescent lamps without integrated ballast. PL stands for Public as these lamps are mainly used in public spaces, corridors, offices and as orientation lighting. This PL LED series has the same shape and size as its fluorescent predecessors. In addition, just like their predecessor, they are made of glass, which ensures the same uniform light image. They are therefore a 1-on-1 sustainable replacements. Connect directly to mains voltage (AC). Not for use with Electronic Ballast (HF/ECG), disconnect ballast before use! Always read the manual carefully before installation.

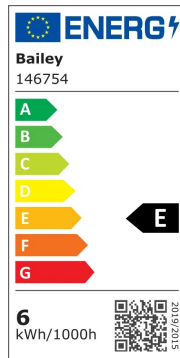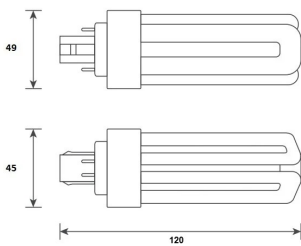

### General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED PL Glass TC-TEL GX24q 4P 6W (18W) 800lm 830 AC
Brand	Bailey
Productseries	LED PL Glass
Producttype	GX24q 4P AC

## ETIM specifications

Socket	Other
Luminous flux [lm]	800 - 800
Nominal voltage [V]	220 - 240
Lamp power [W]	6 - 6
Colour temperature [K]	3000 - 3000
Diameter [mm]	49
Length [mm]	120
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	360 - 360
Colour	White
Type of glass/cover	Opal
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	800
Power factor	0.5
Lamp efficacy [lm/W]	133
Nominal current [mA]	48 - 48
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	30000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM5
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	6
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	Yes
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

---

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	E
With twilight switch	No
Material of light bulb	Glass

---

### Alternative articles



146345  
DULUX T/E LED GX24q-2 HF &  
AC 7W (18W) 830