


The Yale logo is a yellow circle with the word "Yale" in black, bold, sans-serif font.

Disc Iron Padlocks

With over 180 years of manufacturing expertise, the Yale Disc Iron Padlocks have been built with you in mind.

Available in different sizes and standard and long shackle, our Disc Iron Padlock is suitable for a garden shed, gates, shutter doors or any other outdoor high value items you want to keep safe and secure.

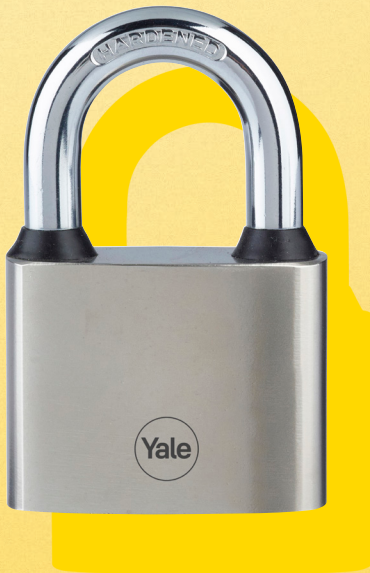

Suitable for



Outdoors



Sheds



Gates

- Disc type locking mechanism makes it harder to pick
- Hardened steel shackle prevents cutting
- Tested to EN12320:2012 for different forms of attack such as cutting, twisting and pulling
- Durable lock tested to 10,000 cycles (opening & closing) for optimum performance
- Excellent corrosion resistance
- Key retaining - key stays in the lock when it is opened and can only be removed when the padlock is locked

Trusted every day



								
Description	30mm Standard Shackle Iron Disc Padlock	30mm Long Shackle Iron Disc Padlock	40mm Standard Shackle Iron Disc Padlock	40mm Long Shackle Iron Disc Padlock	50mm Standard Shackle Iron Disc Padlock	50mm Long Shackle Iron Disc Padlock	60mm Standard Shackle Iron Disc Padlock	70mm Standard Shackle Iron Disc Padlock
Padlock Part no.	Y112/30/121/1	Y112/30/137/1	Y112/40/124/1	Y112/40/138/1	Y112/50/128/1	Y112/50/165/1	Y112/60/132/1	Y112/70/137/1
Locking points	Double locking	Double locking	Double locking	Double locking	Double locking	Double locking	Double locking	Double locking
Body material	Iron	Iron	Iron	Iron	Iron	Iron	Iron	Iron
Shackle material	Hardened steel	Hardened steel	Hardened steel	Hardened steel	Hardened steel	Hardened steel	Hardened steel	Hardened steel
Vertical shackle clearance	21mm	37mm	24.8mm	38mm	28.5mm	65.6mm	32mm	37mm
Horizontal shackle clearance	15mm	15mm	20mm	20mm	25mm	25mm	30mm	35mm
Weight with keys	90.4g	97.8g	128.1g	134.4g	203.9g	228g	299.4g	576g
Dimensions	Body W: 30 Body H: 26 Body D: 15 Shackle Ø: 4.9	Body W: 30 Body H: 26 Body D: 15 Shackle Ø: 4.9	Body W: 40 Body H: 33 Body D: 21 Shackle Ø: 7	Body W: 40 Body H: 33 Body D: 21 Shackle Ø: 7	Body W: 50 Body H: 39 Body D: 23 Shackle Ø: 9	Body W: 50 Body H: 39 Body D: 23 Shackle Ø: 9	Body W: 60 Body H: 45 Body D: 25 Shackle Ø: 11	x Body W: 70 Body H: 51 Body D: 27 Shackle Ø: 13
Corrosion resistance	240 hours	240 hours	240 hours	240 hours	240 hours	240 hours	240 hours	240 hours
Keys	3 keys	3 keys	3 keys	3 keys	3 keys	3 keys	3 keys	3 keys
CEN Rating	1	1	2	2	2	2	2	2