


Deep groove ball bearings, single row, seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
30	55	13	13,8	8,3	0,355	-	8000	0,12	6006-2RS1 *

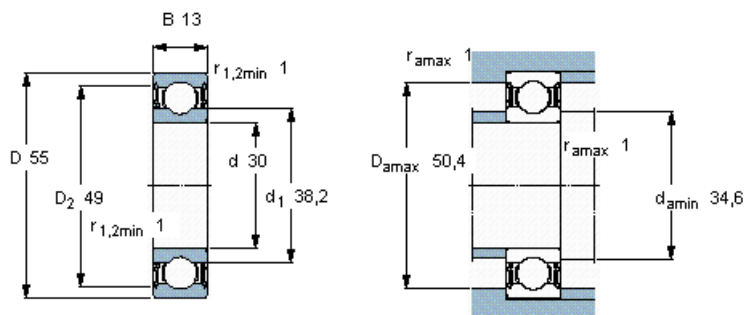

Calculation factors

k_r 0,025

f_0 15