



EI-35X15 SERIES



GS & UK Adaptor (CE Approved)

Reliable
Safety isolating transformer

Class E

Applications

For General Equipment

Safety Applications

GS Adaptor: TUV/GS

UK Adaptor: CE BS 1363 STANDARD

ELECTRICAL CHARACTERISTICS

AC/DC Adaptor

Input Voltage / Frequency: 230VAC 50Hz

Output Voltage: DC 3V-24V

Output Current: 100-500mA

Output Power: 0.3-3.6VA

AC/AC Adaptor

Input Voltage / Frequency: 230VAC 50Hz

Output Voltage: AC 4.5V~24V

Output Current: 230-600mA

Output Power: 2.7-5.52VA

Mechanical Characteristics


GS Adaptor

Length:72.0mm Height:36.8mm
Width:50.0mm Weight:210g


UK Adaptor

Length:58.0mm Height:38.0mm
Width:50.0mm Weight:200g

GS Adaptor Dimension Diagram Unit: mm

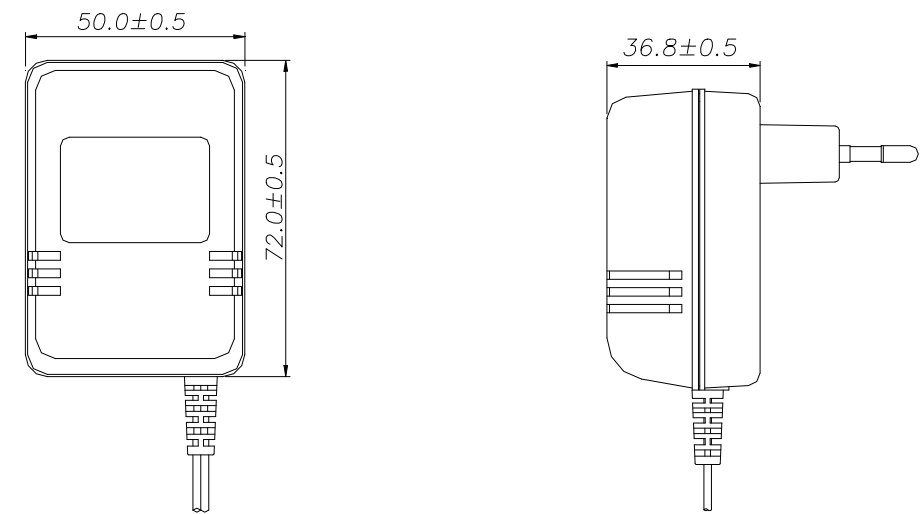

UK Adaptor Dimension Diagram Unit: mm

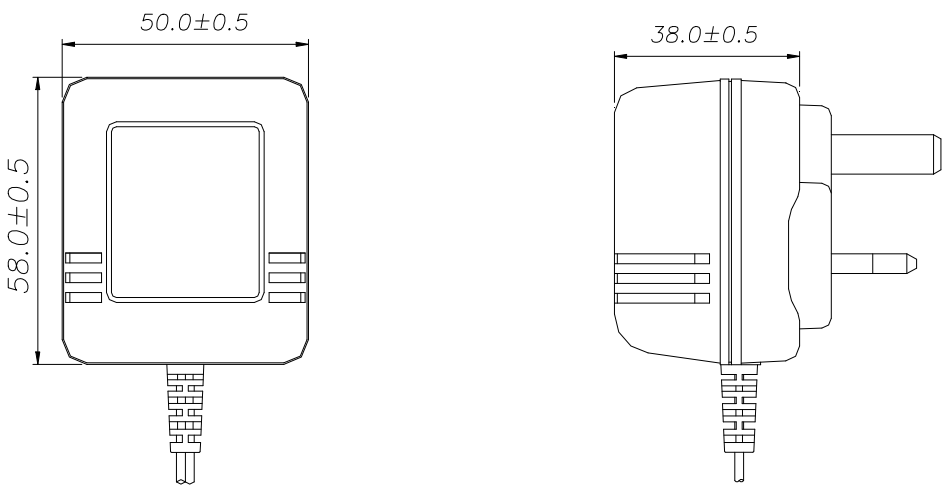

D35 GS & UK AC/DC Adaptor Series Model List

No	Model No.	DC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
1	D35-03.0-YYY	3.0	100	500	0.30	1.50
2	D35-03.1-YYY	3.1	100	500	0.31	1.55
3	D35-03.2-YYY	3.2	100	500	0.32	1.60
4	D35-03.3-YYY	3.3	100	500	0.33	1.65
5	D35-03.4-YYY	3.4	100	500	0.34	1.70
6	D35-03.5-YYY	3.5	100	500	0.35	1.75
7	D35-03.6-YYY	3.6	100	500	0.36	1.80
8	D35-03.7-YYY	3.7	100	500	0.37	1.85
9	D35-03.8-YYY	3.8	100	500	0.38	1.90
10	D35-03.9-YYY	3.9	100	500	0.39	1.95
11	D35-04.0-YYY	4.0	100	500	0.40	2.00
12	D35-04.1-YYY	4.1	100	500	0.41	2.05
13	D35-04.2-YYY	4.2	100	500	0.42	2.10
14	D35-04.3-YYY	4.3	100	500	0.43	2.15
15	D35-04.4-YYY	4.4	100	500	0.44	2.20
16	D35-04.5-YYY	4.5	100	500	0.45	2.25
17	D35-04.6-YYY	4.6	100	500	0.46	2.30
18	D35-04.7-YYY	4.7	100	500	0.47	2.35
19	D35-04.8-YYY	4.8	100	500	0.48	2.40
20	D35-04.9-YYY	4.9	100	500	0.49	2.45
21	D35-05.0-YYY	5.0	100	500	0.50	2.50
22	D35-05.1-YYY	5.1	100	500	0.51	2.55
23	D35-05.2-YYY	5.2	100	500	0.52	2.60
24	D35-05.3-YYY	5.3	100	500	0.53	2.65
25	D35-05.4-YYY	5.4	100	500	0.54	2.70
26	D35-05.5-YYY	5.5	100	500	0.55	2.75
27	D35-05.6-YYY	5.6	100	500	0.56	2.80
28	D35-05.7-YYY	5.7	100	500	0.57	2.85
29	D35-05.8-YYY	5.8	100	500	0.58	2.90
30	D35-05.9-YYY	5.9	100	500	0.59	2.95
31	D35-06.0-YYY	6.0	100	500	0.60	3.00
32	D35-06.1-YYY	6.1	100	492	0.61	3.00
33	D35-06.2-YYY	6.2	100	484	0.62	3.00
34	D35-06.3-YYY	6.3	100	476	0.63	3.00
35	D35-06.4-YYY	6.4	100	469	0.64	3.00
36	D35-06.5-YYY	6.5	100	462	0.65	3.00
37	D35-06.6-YYY	6.6	100	455	0.66	3.00
38	D35-06.7-YYY	6.7	100	448	0.67	3.00
39	D35-06.8-YYY	6.8	100	441	0.68	3.00
40	D35-06.9-YYY	6.9	100	435	0.69	3.00
41	D35-07.0-YYY	7.0	100	429	0.70	3.00
42	D35-07.1-YYY	7.1	100	423	0.71	3.00
43	D35-07.2-YYY	7.2	100	417	0.72	3.00
44	D35-07.3-YYY	7.3	100	411	0.73	3.00
45	D35-07.4-YYY	7.4	100	405	0.74	3.00
46	D35-07.5-YYY	7.5	100	400	0.75	3.00
47	D35-07.6-YYY	7.6	100	400	0.76	3.04

No	Model No.	DC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
48	D35-07.7-YYY	7.7	100	400	0.77	3.08
49	D35-07.8-YYY	7.8	100	400	0.78	3.12
50	D35-07.9-YYY	7.9	100	400	0.79	3.16
51	D35-08.0-YYY	8.0	100	400	0.80	3.20
52	D35-08.1-YYY	8.1	100	400	0.81	3.24
53	D35-08.2-YYY	8.2	100	400	0.82	3.28
54	D35-08.3-YYY	8.3	100	400	0.83	3.32
55	D35-08.4-YYY	8.4	100	400	0.84	3.36
56	D35-08.5-YYY	8.5	100	400	0.85	3.40
57	D35-08.6-YYY	8.6	100	400	0.86	3.44
58	D35-08.7-YYY	8.7	100	400	0.87	3.48
59	D35-08.8-YYY	8.8	100	400	0.88	3.52
60	D35-08.9-YYY	8.9	100	400	0.89	3.56
61	D35-09.0-YYY	9.0	100	400	0.90	3.60
62	D35-09.1-YYY	9.1	100	396	0.91	3.60
63	D35-09.2-YYY	9.2	100	391	0.92	3.60
64	D35-09.3-YYY	9.3	100	387	0.93	3.60
65	D35-09.4-YYY	9.4	100	383	0.94	3.60
66	D35-09.5-YYY	9.5	100	379	0.95	3.60
67	D35-09.6-YYY	9.6	100	375	0.96	3.60
68	D35-09.7-YYY	9.7	100	371	0.97	3.60
69	D35-09.8-YYY	9.8	100	367	0.98	3.60
70	D35-09.9-YYY	9.9	100	364	0.99	3.60
71	D35-10.0-YYY	10.0	100	360	1.00	3.60
72	D35-10.1-YYY	10.1	100	356	1.01	3.60
73	D35-10.2-YYY	10.2	100	353	1.02	3.60
74	D35-10.3-YYY	10.3	100	350	1.03	3.60
75	D35-10.4-YYY	10.4	100	346	1.04	3.60
76	D35-10.5-YYY	10.5	100	343	1.05	3.60
77	D35-10.6-YYY	10.6	100	340	1.06	3.60
78	D35-10.7-YYY	10.7	100	336	1.07	3.60
79	D35-10.8-YYY	10.8	100	333	1.08	3.60
80	D35-10.9-YYY	10.9	100	330	1.09	3.60
81	D35-11.0-YYY	11.0	100	327	1.10	3.60
82	D35-11.1-YYY	11.1	100	324	1.11	3.60
83	D35-11.2-YYY	11.20	100	321	1.12	3.60
84	D35-11.3-YYY	11.3	100	319	1.13	3.60
85	D35-11.4-YYY	11.4	100	316	1.14	3.60
86	D35-11.5-YYY	11.5	100	313	1.15	3.60
87	D35-11.6-YYY	11.6	100	310	1.16	3.60
88	D35-11.7-YYY	11.7	100	308	1.17	3.60
89	D35-11.8-YYY	11.8	100	305	1.18	3.60
90	D35-11.9-YYY	11.9	100	303	1.19	3.60
91	D35-12.0-YYY	12.0	100	300	1.20	3.60
92	D35-12.1-YYY	12.1	100	298	1.21	3.60
93	D35-12.2-YYY	12.2	100	295	1.22	3.60
94	D35-12.3-YYY	12.3	100	293	1.23	3.60

No	Model No.	DC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
95	D35-12.4-YYY	12.4	100	290	1.24	3.60
96	D35-12.5-YYY	12.5	100	288	1.25	3.60
97	D35-12.6-YYY	12.6	100	286	1.26	3.60
98	D35-12.7-YYY	12.7	100	283	1.27	3.60
99	D35-12.8-YYY	12.8	100	281	1.28	3.60
100	D35-12.9-YYY	12.9	100	279	1.29	3.60
101	D35-13.0-YYY	13.0	100	277	1.30	3.60
102	D35-13.1-YYY	13.1	100	275	1.31	3.60
103	D35-13.2-YYY	13.2	100	273	1.32	3.60
104	D35-13.3-YYY	13.3	100	271	1.33	3.60
105	D35-13.4-YYY	13.4	100	269	1.34	3.60
106	D35-13.5-YYY	13.5	100	267	1.35	3.60
107	D35-13.6-YYY	13.6	100	265	1.36	3.60
108	D35-13.7-YYY	13.7	100	263	1.37	3.60
109	D35-13.8-YYY	13.8	100	261	1.38	3.60
110	D35-13.9-YYY	13.9	100	259	1.39	3.60
111	D35-14.0-YYY	14.0	100	257	1.40	3.60
112	D35-14.1-YYY	14.1	100	255	1.41	3.60
113	D35-14.2-YYY	14.2	100	254	1.42	3.60
114	D35-14.3-YYY	14.3	100	252	1.43	3.60
115	D35-14.4-YYY	14.4	100	250	1.44	3.60
116	D35-14.5-YYY	14.5	100	248	1.45	3.60
117	D35-14.6-YYY	14.6	100	247	1.46	3.60
118	D35-14.7-YYY	14.7	100	245	1.47	3.60
119	D35-14.8-YYY	14.8	100	243	1.48	3.60
120	D35-14.9-YYY	14.9	100	242	1.49	3.60
121	D35-15.0-YYY	15.0	100	240	1.50	3.60
122	D35-15.1-YYY	15.1	100	238	1.51	3.60
123	D35-15.2-YYY	15.2	100	237	1.52	3.60
124	D35-15.3-YYY	15.3	100	235	1.53	3.60
125	D35-15.4-YYY	15.4	100	234	1.54	3.60
126	D35-15.5-YYY	15.5	100	232	1.55	3.60
127	D35-15.6-YYY	15.6	100	231	1.56	3.60
128	D35-15.7-YYY	15.7	100	229	1.57	3.60
129	D35-15.8-YYY	15.8	100	228	1.58	3.60
130	D35-15.9-YYY	15.9	100	226	1.59	3.60
131	D35-16.0-YYY	16.0	100	225	1.60	3.60
132	D35-16.1-YYY	16.1	100	224	1.61	3.60
133	D35-16.2-YYY	16.2	100	222	1.62	3.60
134	D35-16.3-YYY	16.3	100	221	1.63	3.60
135	D35-16.4-YYY	16.4	100	220	1.64	3.60
136	D35-16.5-YYY	16.5	100	218	1.65	3.60
137	D35-16.6-YYY	16.6	100	217	1.66	3.60
138	D35-16.7-YYY	16.7	100	216	1.67	3.60
139	D35-16.8-YYY	16.8	100	214	1.68	3.60
140	D35-16.9-YYY	16.9	100	213	1.69	3.60
141	D35-17.0-YYY	17.0	100	212	1.70	3.60

No	Model No.	DC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
142	D35-17.1-YYY	17.1	100	211	1.71	3.60
143	D35-17.2-YYY	17.2	100	209	1.72	3.60
144	D35-17.3-YYY	17.3	100	208	1.73	3.60
145	D35-17.4-YYY	17.4	100	207	1.74	3.60
146	D35-17.5-YYY	17.5	100	206	1.75	3.60
147	D35-17.6-YYY	17.6	100	205	1.76	3.60
148	D35-17.7-YYY	17.7	100	203	1.77	3.60
149	D35-17.8-YYY	17.8	100	202	1.78	3.60
150	D35-17.9-YYY	17.9	100	201	1.79	3.60
151	D35-18.0-YYY	18.0	100	200	1.80	3.60
152	D35-18.1-YYY	18.1	100	199	1.81	3.60
153	D35-18.2-YYY	18.2	100	198	1.82	3.60
154	D35-18.3-YYY	18.3	100	197	1.83	3.60
155	D35-18.4-YYY	18.4	100	196	1.84	3.60
156	D35-18.5-YYY	18.5	100	195	1.85	3.60
157	D35-18.6-YYY	18.6	100	194	1.86	3.60
158	D35-18.7-YYY	18.7	100	193	1.87	3.60
159	D35-18.8-YYY	18.8	100	191	1.88	3.60
160	D35-18.9-YYY	18.9	100	190	1.89	3.60
161	D35-19.0-YYY	19.0	100	189	1.90	3.60
162	D35-19.1-YYY	19.1	100	188	1.91	3.60
163	D35-19.2-YYY	19.2	100	188	1.92	3.60
164	D35-19.3-YYY	19.3	100	187	1.93	3.60
165	D35-19.4-YYY	19.4	100	186	1.94	3.60
166	D35-19.5-YYY	19.5	100	185	1.95	3.60
167	D35-19.6-YYY	19.6	100	184	1.96	3.60
168	D35-19.7-YYY	19.7	100	183	1.97	3.60
169	D35-19.8-YYY	19.8	100	182	1.98	3.60
170	D35-19.9-YYY	19.9	100	181	1.99	3.60
171	D35-20.0-YYY	20.0	100	180	2.00	3.60
172	D35-20.1-YYY	20.1	100	179	2.01	3.60
173	D35-20.2-YYY	20.2	100	178	2.02	3.60
174	D35-20.3-YYY	20.3	100	177	2.03	3.60
175	D35-20.4-YYY	20.4	100	176	2.04	3.60
176	D35-20.5-YYY	20.5	100	176	2.05	3.60
177	D35-20.6-YYY	20.6	100	175	2.06	3.60
178	D35-20.7-YYY	20.7	100	174	2.07	3.60
179	D35-20.8-YYY	20.8	100	173	2.08	3.60
180	D35-20.9-YYY	20.9	100	172	2.09	3.60
181	D35-21.0-YYY	21.0	100	171	2.10	3.60
182	D35-21.1-YYY	21.1	100	171	2.11	3.60
183	D35-21.2-YYY	21.2	100	170	2.12	3.60
184	D35-21.3-YYY	21.3	100	169	2.13	3.60
185	D35-21.4-YYY	21.4	100	168	2.14	3.60
186	D35-21.5-YYY	21.5	100	167	2.15	3.60
187	D35-21.6-YYY	21.6	100	167	2.16	3.60
188	D35-21.7-YYY	21.7	100	166	2.17	3.60

No	Model No.	AC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
189	D35-21.8-YYY	21.8	100	165	2.18	3.60
190	D35-21.9-YYY	21.9	100	164	2.19	3.60
191	D35-22.0-YYY	22.0	100	164	2.20	3.60
192	D35-22.1-YYY	22.1	100	163	2.21	3.60
193	D35-22.2-YYY	22.2	100	162	2.22	3.60
194	D35-22.3-YYY	22.3	100	161	2.23	3.60
195	D35-22.4-YYY	22.4	100	161	2.24	3.60
196	D35-22.5-YYY	22.5	100	160	2.25	3.60
197	D35-22.6-YYY	22.6	100	159	2.26	3.60
198	D35-22.7-YYY	22.7	100	159	2.27	3.60
199	D35-22.8-YYY	22.8	100	158	2.28	3.60
200	D35-22.9-YYY	22.9	100	157	2.29	3.60
201	D35-23.0-YYY	23.0	100	157	2.30	3.60
202	D35-23.1-YYY	23.1	100	156	2.31	3.60
203	D35-23.2-YYY	23.2	100	155	2.32	3.60
204	D35-23.3-YYY	23.3	100	155	2.33	3.60
205	D35-23.4-YYY	23.4	100	154	2.34	3.60
206	D35-23.5-YYY	23.5	100	153	2.35	3.60
207	D35-23.6-YYY	23.6	100	153	2.36	3.60
208	D35-23.7-YYY	23.7	100	152	2.37	3.60
209	D35-23.8-YYY	23.8	100	151	2.38	3.60
210	D35-23.9-YYY	23.9	100	151	2.39	3.60
211	D35-24.0-YYY	24.0	100	150	2.40	3.60

AD3515 GS & UK AC/AC Adaptor Series Model List

No	Model No.	AC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
1	AD3515-04.5-YYY	4.5	600	600	2.70	2.70
2	AD3515-04.6-YYY	4.6	587	600	2.70	2.76
3	AD3515-04.7-YYY	4.7	574	600	2.70	2.82
4	AD3515-04.8-YYY	4.8	563	600	2.70	2.88
5	AD3515-04.9-YYY	4.9	551	600	2.70	2.94
6	AD3515-05.0-YYY	5.0	540	600	2.70	3.00
7	AD3515-05.1-YYY	5.1	529	600	2.70	3.06
8	AD3515-05.2-YYY	5.2	519	600	2.70	3.12
9	AD3515-05.3-YYY	5.3	509	600	2.70	3.18
10	AD3515-05.4-YYY	5.4	500	600	2.70	3.24
11	AD3515-05.5-YYY	5.5	491	600	2.70	3.30
12	AD3515-05.6-YYY	5.6	482	600	2.70	3.36
13	AD3515-05.7-YYY	5.7	474	600	2.70	3.42
14	AD3515-05.8-YYY	5.8	466	600	2.70	3.48
15	AD3515-05.9-YYY	5.9	458	600	2.70	3.54
16	AD3515-06.0-YYY	6.0	450	600	2.70	3.60
17	AD3515-06.1-YYY	6.1	443	600	2.70	3.66
18	AD3515-06.2-YYY	6.2	435	600	2.70	3.72
19	AD3515-06.3-YYY	6.3	429	600	2.70	3.78
20	AD3515-06.4-YYY	6.4	422	600	2.70	3.84
21	AD3515-06.5-YYY	6.5	415	600	2.70	3.90
22	AD3515-06.6-YYY	6.6	409	600	2.70	3.96
23	AD3515-06.7-YYY	6.7	403	600	2.70	4.02
24	AD3515-06.8-YYY	6.8	397	600	2.70	4.08
25	AD3515-06.9-YYY	6.9	391	600	2.70	4.14
26	AD3515-07.0-YYY	7.0	386	600	2.70	4.20
27	AD3515-07.1-YYY	7.1	380	600	2.70	4.26
28	AD3515-07.2-YYY	7.2	375	600	2.70	4.32
29	AD3515-07.3-YYY	7.3	370	600	2.70	4.38
30	AD3515-07.4-YYY	7.4	365	600	2.70	4.44
31	AD3515-07.5-YYY	7.5	360	600	2.70	4.50
32	AD3515-07.6-YYY	7.6	355	600	2.70	4.56
33	AD3515-07.7-YYY	7.7	351	600	2.70	4.62
34	AD3515-07.8-YYY	7.8	346	600	2.70	4.68
35	AD3515-07.9-YYY	7.9	342	600	2.70	4.74
36	AD3515-08.0-YYY	8.0	338	594	2.70	4.75
37	AD3515-08.1-YYY	8.1	333	586	2.70	4.75
38	AD3515-08.2-YYY	8.2	329	579	2.70	4.75
39	AD3515-08.3-YYY	8.3	325	572	2.70	4.75
40	AD3515-08.4-YYY	8.4	321	565	2.70	4.75
41	AD3515-08.5-YYY	8.5	318	559	2.70	4.75
42	AD3515-08.6-YYY	8.6	314	552	2.70	4.75
43	AD3515-08.7-YYY	8.7	310	546	2.70	4.75
44	AD3515-08.8-YYY	8.8	307	540	2.70	4.75
45	AD3515-08.9-YYY	8.9	303	534	2.70	4.75
46	AD3515-09.0-YYY	9.0	300	528	2.70	4.75
47	AD3515-09.1-YYY	9.1	297	522	2.70	4.75

No	Model No.	AC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
48	AD3515-09.2-YYY	9.2	293	516	2.70	4.75
49	AD3515-09.3-YYY	9.3	290	511	2.70	4.75
50	AD3515-09.4-YYY	9.4	287	505	2.70	4.75
51	AD3515-09.5-YYY	9.5	284	500	2.70	4.75
52	AD3515-09.6-YYY	9.6	281	495	2.70	4.75
53	AD3515-09.7-YYY	9.7	278	490	2.70	4.75
54	AD3515-09.8-YYY	9.8	276	485	2.70	4.75
55	AD3515-09.9-YYY	9.9	273	480	2.70	4.75
56	AD3515-10.0-YYY	10.0	270	475	2.70	4.75
57	AD3515-10.1-YYY	10.1	267	470	2.70	4.75
58	AD3515-10.2-YYY	10.2	265	466	2.70	4.75
59	AD3515-10.3-YYY	10.3	262	461	2.70	4.75
60	AD3515-10.4-YYY	10.4	260	457	2.70	4.75
61	AD3515-10.5-YYY	10.5	257	452	2.70	4.75
62	AD3515-10.6-YYY	10.6	255	448	2.70	4.75
63	AD3515-10.7-YYY	10.7	252	444	2.70	4.75
64	AD3515-10.8-YYY	10.8	250	440	2.70	4.75
65	AD3515-10.9-YYY	10.9	248	436	2.70	4.75
66	AD3515-11.0-YYY	11.0	245	432	2.70	4.75
67	AD3515-11.1-YYY	11.1	243	428	2.70	4.75
68	AD3515-11.2-YYY	11.2	241	424	2.70	4.75
69	AD3515-11.3-YYY	11.3	239	420	2.70	4.75
70	AD3515-11.4-YYY	11.4	237	417	2.70	4.75
71	AD3515-11.5-YYY	11.5	235	413	2.70	4.75
72	AD3515-11.6-YYY	11.6	233	409	2.70	4.75
73	AD3515-11.7-YYY	11.7	231	406	2.70	4.75
74	AD3515-11.8-YYY	11.8	230	403	2.71	4.75
75	AD3515-11.9-YYY	11.9	230	400	2.74	4.76
76	AD3515-12.0-YYY	12.0	230	400	2.76	4.80
77	AD3515-12.1-YYY	12.1	230	397	2.78	4.80
78	AD3515-12.2-YYY	12.2	230	393	2.81	4.80
79	AD3515-12.3-YYY	12.3	230	390	2.83	4.80
80	AD3515-12.4-YYY	12.4	230	387	2.85	4.80
81	AD3515-12.5-YYY	12.5	230	384	2.88	4.80
82	AD3515-12.6-YYY	12.6	230	381	2.90	4.80
83	AD3515-12.7-YYY	12.7	230	378	2.92	4.80
84	AD3515-12.8-YYY	12.8	230	375	2.94	4.80
85	AD3515-12.9-YYY	12.9	230	372	2.97	4.80
86	AD3515-13.0-YYY	13.0	230	369	2.99	4.80
87	AD3515-13.1-YYY	13.1	230	366	3.01	4.80
88	AD3515-13.2-YYY	13.2	230	364	3.04	4.80
89	AD3515-13.3-YYY	13.3	230	361	3.06	4.80
90	AD3515-13.4-YYY	13.4	230	358	3.08	4.80
91	AD3515-13.5-YYY	13.5	230	356	3.11	4.80
92	AD3515-13.6-YYY	13.6	230	353	3.13	4.80
93	AD3515-13.7-YYY	13.7	230	350	3.15	4.80
94	AD3515-13.8-YYY	13.8	230	348	3.17	4.80

No	Model No.	AC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
95	AD3515-13.9-YYY	13.9	230	345	3.20	4.80
96	AD3515-14.0-YYY	14.0	230	343	3.22	4.80
97	AD3515-14.1-YYY	14.1	230	340	3.24	4.80
98	AD3515-14.2-YYY	14.2	230	338	3.27	4.80
99	AD3515-14.3-YYY	14.3	230	336	3.29	4.80
100	AD3515-14.4-YYY	14.4	230	333	3.31	4.80
101	AD3515-14.5-YYY	14.5	230	331	3.34	4.80
102	AD3515-14.6-YYY	14.6	230	329	3.36	4.80
103	AD3515-14.7-YYY	14.7	230	327	3.38	4.80
104	AD3515-14.8-YYY	14.8	230	324	3.40	4.80
105	AD3515-14.9-YYY	14.9	230	322	3.43	4.80
106	AD3515-15.0-YYY	15.0	230	320	3.45	4.80
107	AD3515-15.1-YYY	15.1	230	318	3.47	4.80
108	AD3515-15.2-YYY	15.2	230	316	3.50	4.80
109	AD3515-15.3-YYY	15.3	230	314	3.52	4.80
110	AD3515-15.4-YYY	15.4	230	312	3.54	4.80
111	AD3515-15.5-YYY	15.5	230	310	3.57	4.80
112	AD3515-15.6-YYY	15.6	230	308	3.59	4.80
113	AD3515-15.7-YYY	15.7	230	306	3.61	4.80
114	AD3515-15.8-YYY	15.8	230	304	3.63	4.80
115	AD3515-15.9-YYY	15.9	230	302	3.66	4.80
116	AD3515-16.0-YYY	16.0	230	300	3.68	4.80
117	AD3515-16.1-YYY	16.1	230	298	3.70	4.80
118	AD3515-16.2-YYY	16.2	230	296	3.73	4.80
119	AD3515-16.3-YYY	16.3	230	294	3.75	4.80
120	AD3515-16.4-YYY	16.4	230	293	3.77	4.80
121	AD3515-16.5-YYY	16.5	230	291	3.80	4.80
122	AD3515-16.6-YYY	16.6	230	289	3.82	4.80
123	AD3515-16.7-YYY	16.7	230	287	3.84	4.80
124	AD3515-16.8-YYY	16.8	230	286	3.86	4.80
125	AD3515-16.9-YYY	16.9	230	284	3.89	4.80
126	AD3515-17.0-YYY	17.0	230	282	3.91	4.80
127	AD3515-17.1-YYY	17.1	230	281	3.93	4.80
128	AD3515-17.2-YYY	17.2	230	279	3.96	4.80
129	AD3515-17.3-YYY	17.3	230	277	3.98	4.80
130	AD3515-17.4-YYY	17.4	230	276	4.00	4.80
131	AD3515-17.5-YYY	17.5	230	274	4.03	4.80
132	AD3515-17.6-YYY	17.6	230	273	4.05	4.80
133	AD3515-17.7-YYY	17.7	230	271	4.07	4.80
134	AD3515-17.8-YYY	17.8	230	270	4.09	4.80
135	AD3515-17.9-YYY	17.9	230	268	4.12	4.80
136	AD3515-18.0-YYY	18.0	230	267	4.14	4.80
137	AD3515-18.1-YYY	18.1	230	265	4.16	4.80
138	AD3515-18.2-YYY	18.2	230	264	4.19	4.80
139	AD3515-18.3-YYY	18.3	230	262	4.21	4.80
140	AD3515-18.4-YYY	18.4	230	261	4.23	4.80
141	AD3515-18.5-YYY	18.5	230	259	4.26	4.80

No	Model No.	AC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
142	AD3515-18.6-YYY	18.6	230	258	4.28	4.80
143	AD3515-18.7-YYY	18.7	230	257	4.30	4.80
144	AD3515-18.8-YYY	18.8	230	255	4.32	4.80
145	AD3515-18.9-YYY	18.9	230	254	4.35	4.80
146	AD3515-19.0-YYY	19.0	230	253	4.37	4.80
147	AD3515-19.1-YYY	19.1	230	251	4.39	4.80
148	AD3515-19.2-YYY	19.2	230	250	4.42	4.80
149	AD3515-19.3-YYY	19.3	230	249	4.44	4.80
150	AD3515-19.4-YYY	19.4	230	247	4.46	4.80
151	AD3515-19.5-YYY	19.5	230	246	4.49	4.80
152	AD3515-19.6-YYY	19.6	230	245	4.51	4.80
153	AD3515-19.7-YYY	19.7	230	244	4.53	4.80
154	AD3515-19.8-YYY	19.8	230	242	4.55	4.80
155	AD3515-19.9-YYY	19.9	230	241	4.58	4.80
156	AD3515-20.0-YYY	20.0	230	240	4.60	4.80
157	AD3515-20.1-YYY	20.1	230	240	4.62	4.82
158	AD3515-20.2-YYY	20.2	230	240	4.65	4.85
159	AD3515-20.3-YYY	20.3	230	240	4.67	4.87
160	AD3515-20.4-YYY	20.4	230	240	4.69	4.90
161	AD3515-20.5-YYY	20.5	230	240	4.72	4.92
162	AD3515-20.6-YYY	20.6	230	240	4.74	4.94
163	AD3515-20.7-YYY	20.7	230	240	4.76	4.97
164	AD3515-20.8-YYY	20.8	230	240	4.78	4.99
165	AD3515-20.9-YYY	20.9	230	240	4.81	5.02
166	AD3515-21.0-YYY	21.0	230	240	4.83	5.04
167	AD3515-21.1-YYY	21.1	230	240	4.85	5.06
168	AD3515-21.2-YYY	21.2	230	240	4.88	5.09
169	AD3515-21.3-YYY	21.3	230	240	4.90	5.11
170	AD3515-21.4-YYY	21.4	230	240	4.92	5.14
171	AD3515-21.5-YYY	21.5	230	240	4.95	5.16
172	AD3515-21.6-YYY	21.6	230	240	4.97	5.18
173	AD3515-21.7-YYY	21.7	230	240	4.99	5.21
174	AD3515-21.8-YYY	21.8	230	240	5.01	5.23
175	AD3515-21.9-YYY	21.9	230	240	5.04	5.26
176	AD3515-22.0-YYY	22.0	230	240	5.06	5.28
177	AD3515-22.1-YYY	22.1	230	240	5.08	5.30
178	AD3515-22.2-YYY	22.2	230	240	5.11	5.33
179	AD3515-22.3-YYY	22.3	230	240	5.13	5.35
180	AD3515-22.4-YYY	22.4	230	240	5.15	5.38
181	AD3515-22.5-YYY	22.5	230	240	5.18	5.40
182	AD3515-22.6-YYY	22.6	230	240	5.20	5.42
183	AD3515-22.7-YYY	22.7	230	240	5.22	5.45
184	AD3515-22.8-YYY	22.8	230	240	5.24	5.47
185	AD3515-22.9-YYY	22.9	230	240	5.27	5.50
186	AD3515-23.0-YYY	23.0	230	240	5.29	5.52
187	AD3515-23.1-YYY	23.1	230	239	5.31	5.52
188	AD3515-23.2-YYY	23.2	230	238	5.34	5.52

No	Model No.	AC output voltage (V)	Min. Rated output current (mA)	Max. Rated output current (mA)	Min. output power (VA)	Max. output power (VA)
189	AD3515-23.3-YYY	23.3	230	237	5.36	5.52
190	AD3515-23.4-YYY	23.4	230	236	5.38	5.52
191	AD3515-23.5-YYY	23.5	230	235	5.41	5.52
192	AD3515-23.6-YYY	23.6	230	234	5.43	5.52
193	AD3515-23.7-YYY	23.7	230	233	5.45	5.52
194	AD3515-23.8-YYY	23.8	230	232	5.47	5.52
195	AD3515-23.9-YYY	23.9	230	231	5.50	5.52
196	AD3515-24.0-YYY	24.0	230	230	5.52	5.52