



Starters for tanning lamps

S16 70-125W 240V UNP

Range of premium-quality starters for igniting fluorescent lamps operating on electromagnetic ballasts

Product data

• General Characteristics

System Description	Single
Cap-Base Information	2P
Colour of the Housing	White

• Electrical Characteristics

Lamp Wattage	70-125 W
Voltage	240 V
Pulse Voltage	900 (min) V
Non Reclosure Voltage	170 (min) V
Capacitor	yes

• Luminaire Design Requirements

Ambient Temperature	0 (min), 55 (max) C
---------------------	---------------------

• Product Dimensions

Overall Length C	40.3 (max) mm
Overall Width E	21.5 (max) mm

• Product Data

Order code	903563 28
Full product code	871150090356328
Full product name	S16 70-125W 240V UNP
Order product name	S16 70-125W 240V UNP/1000
Pieces per pack	1
Packing configuration	1000
Packs per outerbox	1000
Bar code on pack - EAN1	8711500903563
Bar code on outerbox - EAN3	8711500903594
Logistic code(s) - 12NC	928390930355
Net weight per piece	7.280 gr


• UV-resistant canister

Warnings and Safety

- Flame-retardant components

PHILIPS

Dimensional drawing

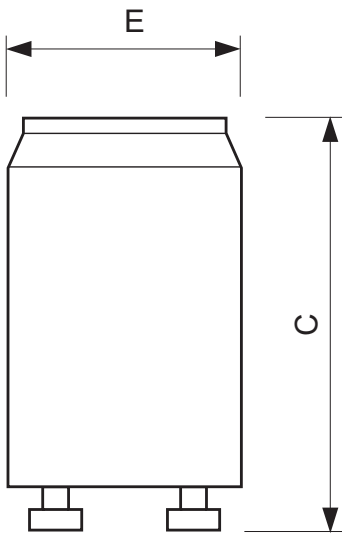

S16 70-125W 240V UNP

Product	C (Max)	E (Max)
S16 70-125W SIN 240V WH	40.3	21.5



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, April 10
data subject to change