

 
 
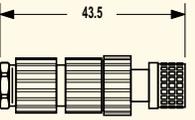
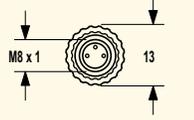
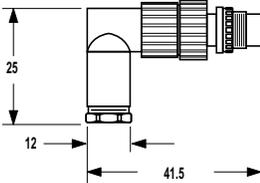
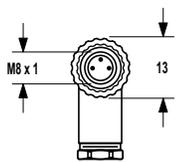
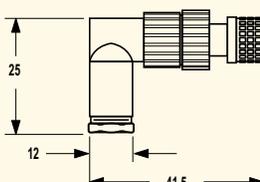
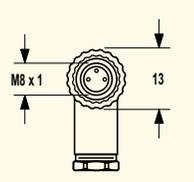
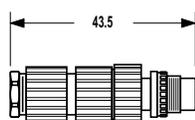
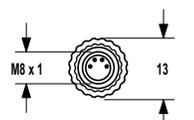
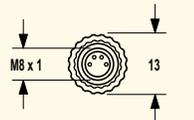
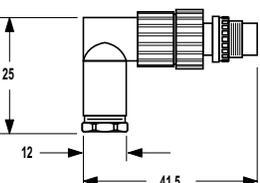
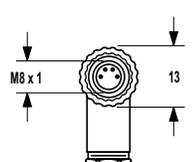
## Pico-Style Field-Wireable Connectors (M8)

Contacts: Gold-plated, rated 60V ac/dc max., 4.0 A max.

Cable Diameter: 4.0 to 5.0 mm

Temperature: -25° to +70° C

Environmental Rating: NEMA 6P, IP67

Style	Model	Dimensions	Pinout
3-Pin Male Straight	FIC-M8M3		
3-Pin Female Straight	FIC-M8F3		
3-Pin Male Right-Angle	FIC-M8M3A		
3-Pin Female Right-Angle	FIC-M8F3A		
4-Pin Male Straight	FIC-M8M4		
4-Pin Female Straight	FIC-M8F4		
4-Pin Male Right-Angle	FIC-M8M4A		
4-Pin Female Right-Angle	FIC-M8F4A	