

Actuator

46-
2COP.1920.000

Distribution by
Rs-online



<https://www.rs-online.eao.com/component/46-2C...>

Your product:



46-2C0P.1920.000 Actuator

Loading ...

FRONT

Front dimension: Ø 40 mm

Front form: Round

MOUNTING

Design: Raised

Mounting cut-out: Ø 22.3 mm

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens colour: Red

Lens material: Plastic

Lens illumination: Illuminated

Lens shape: Mushroom-head

Lens optics: translucent

Illumination colour: Red

ELECTRICAL CHARACTERISTICS

Pollution degree: 3

Protection class: II, according to EN / IEC 61140

MECHANICAL CHARACTERISTICS

Release type: Twist / Pull to unlock

Mechanical lifetime:	500 000 cycles of operation
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Weight:	0.036 kg

AMBIENT CONDITION


IP front protection:	IP66
IK front protection:	IK03
Operating temperature:	– 40 °C ... + 70 °C
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE

Conformities:	CE
REACH:	REACH compliant
RoHS:	RoHS compliant
Standards:	CEI EN 61373, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UNI EN ISO 12100, UNI EN ISO 13850

OTHER

Short Description:	Actuator, Ø 22.3 mm, Ø 40 mm, Mushroom-head, Illuminated, Red, Plastic, translucent, Round, IP66, IK03, Twist / Pull to unlock, Red
Dimension:	Ø 40 mm
Housing colour:	Yellow
Housing material:	Plastic
max. number of switching elements:	4
Mounting cut-outs:	

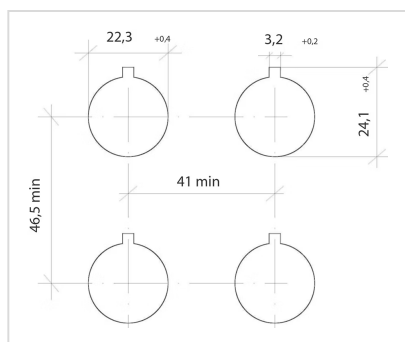

Dimension drawings:

