

Start Spot IP65

START SPOT LED IP65 6.5W 475LM 3000K

0053545



Range Features

- Range of integrated LED value downlights combining high lumen efficacy with great aesthetic
- Available in 3000K and 4000K
- Integrated LED driver with polycarbonate body
- Includes both IP20 and IP65 versions
- Low profile of 58mm (60mm including bezel)
- Bezel dimension 86mm with cutout of 65-74mm

PRODUCT OVERVIEW

Beam angle(°)	100
Certifications	CE
Colour temperature (K)	3000
Colour	White
CRI (Ra)	80
EAN code	5410288535456
Luminous flux (lm)	475
Housing	Polycarbonate
IP rating	IP65
Light colour	Warm white
LOR (%)	100
Mount	Ceiling recessed
Ordering number	0053545
Efficacy (Rated) (lm/w)	73
Average life (Rated) (h)	30000
Technology	LED
Voltage (V)	220-240
Included lamp	Integrated LED

DATA TABLE

General data

Average life (Nominal) (h)	30000
Certifications	CE
EAN code	5410288535456
General application	Residential & Consumer
Housing	Polycarbonate
Mount	Ceiling recessed
Ordering number	0053545

Start Spot IP65

START SPOT LED IP65 6.5W 475LM 3000K

0053545

Range features	<p>Range of integrated LED value downlights combining high lumen efficacy with great aesthetic Available in 3000K and 4000K Integrated LED driver with polycarbonate body Includes both IP20 and IP65 versions Low profile of 58mm (60mm including bezel) Bezel dimension 86mm with cutout of 65-74mm</p>
Product name	START SPOT LED IP65 6.5W 475LM 3000K
Average life (Rated) (h)	30000
Technology	LED
Product features	Integrated LED IP65 fixed downlight, 475LM, 6.5W, 3000K, 100 degree beam angle, polycarbonate white body, low profile 58mm recessed depth, 86mm bezel diameter, 68-74mm cutout, frosted lens.

Optical data

Beam angle(°)	100
Colour temperature (K)	3000
CRI (Ra)	80
Distribution type	Direct
Luminous flux (lm)	475
Light colour	Warm white
LOR (%)	100

Physical data

Colour	White
Cutout diameter (mm)	65-74
Diffuser material	Acrylic
Height (mm)	60
IP rating	IP65
Lamp included	Integrated
Length (mm)	86
Recessed depth (mm)	58
Reflector finish	Frosted
Width (mm)	86
Included lamp	Integrated LED

Electrical data

Electrical protection	CLASS 2
Efficacy (Rated) (lm/w)	73
Total power consumption (W)	6.5
Voltage (V)	220-240


Start Spot IP65

START SPOT LED IP65 6.5W 475LM 3000K


0053545

PHOTOMETRY

0.5	1.28	E(0°) E(10°) E(180°)	82.1°	709 82
1.0	2.57	E(0°) E(10°) E(180°)	82.1°	177 21
1.5	3.85	E(0°) E(10°) E(180°)	82.1°	79 9
2.0	5.14	E(0°) E(10°) E(180°)	82.1°	44 5
2.5	6.42	E(0°) E(10°) E(180°)	82.1°	28 3
3.0	7.71	E(0°) E(10°) E(180°)	82.1°	20 2
Distance [m] Cone diameter [m]				Illuminance [lx]
— C0 - C180 (Half beam angle: 104.2°)				

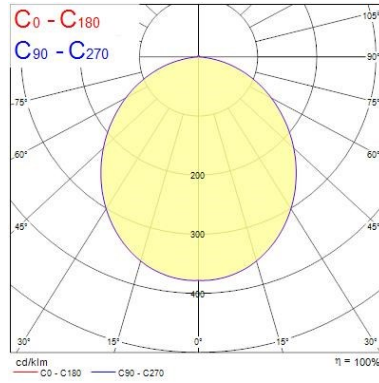

TECHNICAL DRAWINGS

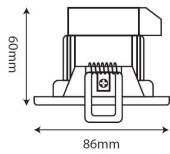



Start Spot IP65

START SPOT LED IP65 6.5W 475LM 3000K


0053545


SYLVANIA 0053545


 This luminaire contains built in LED lamps.

 } **LED**


The lamps cannot be changed in the luminaire.

874/2012 

 This luminaire contains built in LED lamps.

 } **LED**

The lamps cannot be changed in the luminaire.

SYLVANIA 0053545  874/2012