
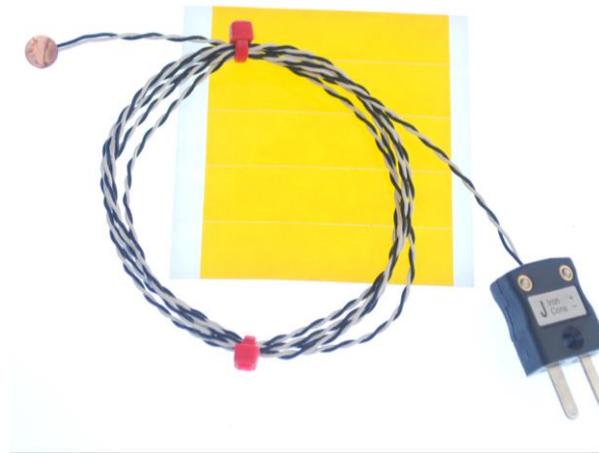


Datasheet

IEC Type K or J 'Copper Disc' Fine Wire Thermocouple with Miniature Plug Termination

1 or 2-metre-long Teflon® PFA insulated lead, supplied complete with adhesive kapton strips

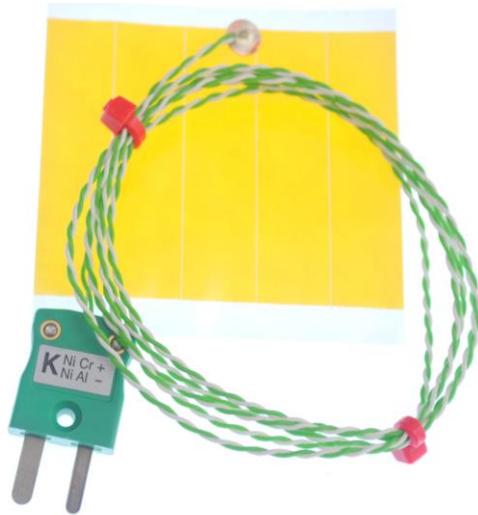

- Exposed junction thermocouple with Copper Disc brazed at tip
- Type 'K' or 'J'
- Fast response – ideal for surface measurement
- High temperature adhesive kapton strips (13x18mm x 5) for quick and easy attachment to surface/process
- Copper disc, 6.35mm diameter x 0.3mm thick
- 1/0.2mm Teflon® insulated twisted wire
- 1 or 2 metre long
- Good mechanical strength and flexibility, resistant to oils, acids and other adverse fluids, steam, gasses etc.
- Ideal for test & development applications
- Temperature range -0°C to 200°C
- Colour coded to IEC 584-2 specification

T/C Type	Conductors	mm ²	Length	Colour Code	Allied code	RS order code
K	1/0.2mm	0.032	1 metre	+Green /-White		131-4739
K	1/0.2mm	0.032	2 metre	+Green /-White		131-4740
J	1/0.2mm	0.032	1 metre	+Black/-White		131-4741
J	1/0.2mm	0.032	2 metre	+Black/-White		131-4742