
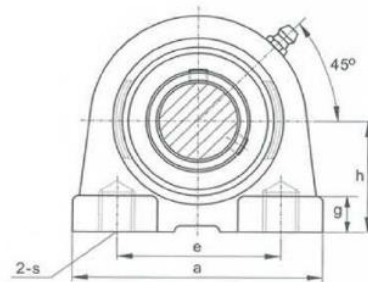


## 2 Bolt Pillow block Tapped base – Metric

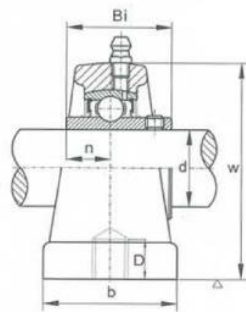

RS Article no.	Bearing unit No.	Shaft Dia.	Dimension (mm)										Bolt used	Bearing No.	Housing No.	Weight (kg)
		d (mm)	h	a	e	b	s	g	w	D	Bi	n	(mm)			
7509015	UCPA204	20	30.2	76	52	40	M10	11	62	13	31.0	12.7	M10	UC 204	PA 204	0.64
7509018	UCPA205	25	36.5	84	56	45	M10	12	72	13	34.0	14.3	M10	UC 205	PA 205	0.83
7509012	UCPA206	30	42.9	94	66	50	M14	12	84	18	38.1	15.9	M14	UC 206	PA 206	1.2
7509021	UCPA207	35	47.6	110	80	55	M14	13	95	20	42.9	17.5	M14	UC 207	PA 207	1.7
7509024	UCPA208	40	49.2	116	84	58	M14	13	100	20	49.2	19.0	M14	UC 208	PA 208	2.0
7509028	UCPA209	45	54.2	120	90	60	M14	13	108	25	49.2	19.0	M14	UC 209	PA 209	2.2
7509037	UCPA210	50	57.2	130	94	64	M16	14	116	25	51.6	19.0	M16	UC 210	PA 210	2.8