


6972H Adaptor, bit holder

DIN 7427 Form A.
 Drive 1/4" DIN 3121-G 6.3 ISO 1174.
Finish: Nickel and chrome-plated.
Material: VANADIUM-EXTRA.
 For screwdriver bits with 1/4" male hexagon drive:
 DIN 3126-C 6,3 ISO 1173. * with spring collar.

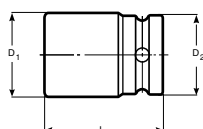

Product code	EAN 731415+				L mm	D2 mm		
6972H	1215934	1	1/4**	1/4"	26.0	13.0	K560F-1	18

6951 Ratchet adaptor

DIN 3122 and 3123.
 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.
 Reversible. 60 teeth. 6° action.
 Max head Ø: 23 mm.



Product code	EAN 731415+			
6951	1089764	1	35	50

6950 Reversible ratchet

DIN 3122 and 3123.
 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.
 With plastic handle. 30 teeth/12° action and with quick release button.



Product code	EAN 731415+			
6950	1089641	1	130	95

6952 Speeder

DIN 3122 and 3123.
 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.
 With a rotatory steel handle.



Product code	EAN 731415+			
6952	1089771	1	410	270

6950RN Reversible ratchet

DIN 3122 and 3123.
 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.
 With plastic handle. 60 teeth/6° action.



Product code	EAN 731415+			
6950RN	1831189	1	130	85

6958 Breaker bar

DIN 3122 and 3123.
 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.
 With plastic handle.


 



Product code	EAN 731415+			
6958	1089849	1	153	95

6963 Flexible extension 1/4"

Finish: Nickel and chrome-plated, fine-polished.
 Not designed for final tightening or initial loosening!


 



Product code	EAN 731415+		 L mm	 g
6963	1089931	1	155	45

6959 – 6962L Extension bars

DIN 3122 and 3123. 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.


 



Product code	EAN 731415+		 L mm	 g
6959	3011817	5	32	15
6960	1089856	5	50	23
6961	1089870	5	100	45
6962	1089894	5	150	65
6962L	1089917	5	355	158

6960-W – 6962-W Extension bars

Wobbler Extension bar. Maximum angle 15°.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.
 Retail packed on a plastic info card.


 



Product code	EAN 731415+		 L mm	 g
6960-W	3010506	10	50	36
6961-W	3010513	10	100	57
6962-W	3010520	10	150	83

6966 Universal joint 1/4"

DIN 3122, 3123 ISO 3316. 1/4" 6.3 DIN 3122/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.




 



Product code	EAN 731415+		 L mm	 g
6966	1089986	1	32.5	18

7765 Adaptor

DIN 3122 and 3123. 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.






 

Product code	EAN 731415+				 L mm	 g
7765	1096687	1	1/4	3/8	25	25

7767 Adaptor

DIN 3123. 1/4" 6.3 and 3/8" 10 DIN 3120 ISO 1174. Adapter 1/4" female square and 3/8" male square.

Finish: Tumbled, high bright galvanised.
Material: Chrome-Vanadium with magnet in the drive disc.
8967/S3 set of 3.



Product code	EAN 731415+				 L mm	 g
7767	3003577	1	1/4"	3/8"	3.0	18
8967/S3	3003607	1			30x194x110	109

6956 Spinner handles with bi-material handle

6956: Black/orange with a 1/4" female square drive in the handle for use as extension bar or to attach sliding T-handle.



Product code	EAN 731415+		L mm	g
6956	1089825	1	150	102

6954 Sliding T-handle

DIN 3122 and 3123. 1/4" 6.3 DIN 3120/ISO 1174.
Finish: Nickel and chrome-plated, fine-polished.
Material: VANADIUM-EXTRA.



Product code	EAN 731415+		L mm	g
6954	1089795	1	125	40

6950-SO/1 Spare parts assortment

For 1/4" ratchet. No. 6950.

Parts: 13. 2 shifters, 1 cover, 1 ratchet gear, 1 ratchet locking wheel, 2 spiral springs, 2 balls, 4 screws.



Product code	EAN 731415+		g
6950-SO/1	1798673	1	23

187/264/340 Socket rails

Socket rails in zinc coated metal with 2 holes for screws, (-340 with 3 holes). On the rail CLIPS-1/4 (1/4"), CLIPS-3/8 (3/8") and CLIPS-1/2 (1/2") can be mounted, fitting sockets or socket drivers, in the respective square size.



Product code	EAN 731415+		L	g
RAIL-187	3003621	3	187	15
RAIL-264	3003638	3	264	20
RAIL-340	3003645	3	340	30

6950-SO/2 Spare parts assortment

Spare part set for 1/4" ratchet for No. 6950.

5 parts: 1 shifter, 1 ratchet gear, 1 ratchet locking wheel, 2 screws.



Product code	EAN 731415+		g
6950-SO/2	111305	1	15

C1/4 Clips

Rail-clips 1/4" for sockets and socket drivers. Nickel plated, spring metal. To be used on RAIL-187, -264 or -340.



Product code	EAN 731415+		L mm	g
CLIPS-1/4	3003188	25	19	1

A6716DM Socket Set

1/4" 6.3 DIN 3120/ISO 1174.

Finish: Nickel and chrome-plated, fine-polished.**Material:** VANADIUM-EXTRA. In red, Skydrol-resistant baked enamelled metal box, with insert of elastic plastic material to hold the tools. Sockets with Dynamic-Drive-Profile™.

Product code	EAN 731415+			
A6716DM	1820824	1	220x110x35	1175
A6700DM 5.5 6 7 8 9 10 11 12 13 14 mm				
6950				
6956				
6954				
6962 150 mm				
6966 150 mm				

A6716DZ Socket Set

1/4" 6.3 DIN 3120/ISO 1174.

Finish: Nickel and chrome-plated, fine-polished.**Material:** VANADIUM-EXTRA. In red, Skydrol-resistant baked enamelled metal box, with insert of elastic plastic material to hold the tools. Sockets with Dynamic-Drive-Profile™.

Product code	EAN 731415+			
A6716DZ	1820831	1	220x110x35	1185
A6700DZ 3/16 7/32 1/4 9/32 5/16 11/32 3/8 7/16 1/2 9/16				
6950				
6956				
6954				
6962 150 mm				
6966				

6715MG Socket Set

1/4" 6.3 DIN 3120/ISO 1174.

Finish: Nickel and chrome-plated, fine-polished.**Material:** VANADIUM-EXTRA. In red, Skydrol-resistant baked enamelled metal box, insert of elastic plastic material to hold the tools. Sockets with Dynamic-Drive-Profile™.

Product code	EAN 731415+			
6715MG	1831349	1	220x110x35	1330
6700SM 4 4.5 5 5.5 6 7 8 9 10 11 12 13 14 mm				
6950RN				
6958				
6956				
6954				
6960 50 mm				
6962 150 mm				
6966				

6721NM Socket Set

1/4" 6.3 DIN 3120/ISO 1174.

Finish: Nickel and chrome-plated, fine-polished.**Material:** VANADIUM-EXTRA. In red, Skydrol-resistant baked enamelled metal box, insert of elastic plastic material to hold the tools. Sockets with Dynamic-Drive-Profile™.

Product code	EAN 731415+			
6721NM	1088309	1	220x110x35	1345
6700SM 4 4.5 5 5.5 6 7 8 9 10 11 12 13 14 mm				
6950				
6958				
6956				
6954				
6960 50 mm				
6962 150 mm				
6951				
6966				