



SANDVIK LINDSTRÖM



80-Series Diagonal cutters

These Tapered and Relieved Head cutters are ideal for use in confined spaces and for rework.

Tapered and relieved head

8146-8158

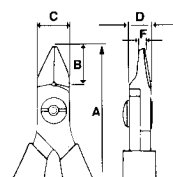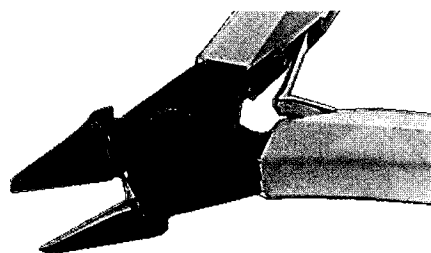

Product code	EAN code 731415+		A mm	B mm	C mm	D mm	F mm	Capacity mm	Bevel	
8146	0051076	1	110	10	10	6	0,8	0,2-1,0	Micro	46
8147	0051083	1	110	10	10	6	0,8	0,1-1,0	Flush	46
8148	0051090	1	110	10	10	6	0,8	0,1-0,8	Ultra	45
8156	0051212	1	112,5	12,5	12,5	6	1,0	0,3-1,25	Micro	49
8157	0052127	1	112,5	12,5	12,5	6	1,0	0,2-1,25	Flush	49
8158	0052134	1	112,5	12,5	12,5	6	1,0	0,2-1,0	Ultra	49



This Tip cutter is ideal for use with multi-lead components and for rework.

Tip cutter

8149

Product code	EAN code 731415+		A mm	B mm	C mm	D mm	G mm	Capacity mm	Bevel	
8149	0051106	1	114	14	5	6	5	0,1-0,6	Flush	48

