



# Datasheet


## RS PRO Stainless steel variable spring toggle latch with hole for lock, 76mm

Stock number: 1929639

EN



- Stainless steel (304) variable sprung toggle latch
- With hole for padlock
- Complete with catchplate

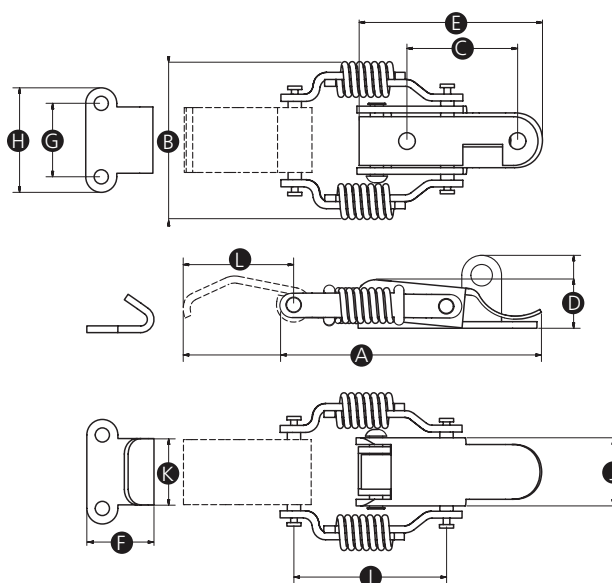

Part No.	A	B	C	D	E	F	G	H	I	J	K	Base hole Size	Hook hole size	Locking hole size	Max load (N)
1929639	76	46	28	22	62	26	25	37	43	24	21	5	5	5.5	1000