




Datasheet

ENGLISH

RS PRO Momentary Foot Switch - Aluminium Case Material, DP-CO, 20 A Contact Current, 125 V, 250 V Contact Voltage


RS stock no: 125-3714

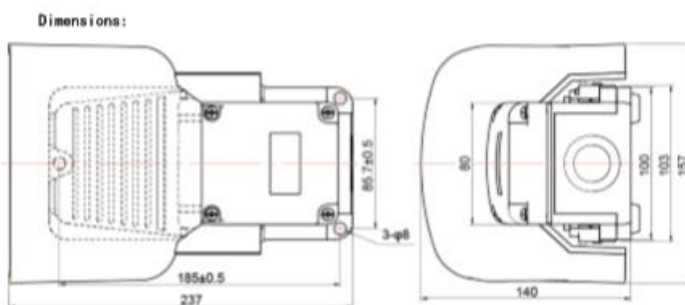

Features and Benefits

- Momentary foot switch
- Guard cover included for added protection
- Anti-skid rubber feet and three holes for rigid mounting to floor or equipment
- Contact configuration of DP-CO
- Orange colour
- Momentary switch operation
- Constructed from cast aluminum
- IP68 rated for dust and water protection
- CCC, CE, CSA, CULus and CULus compliant for safety and quality
- Weight: 2 kg.

 Wiring Drawing:



Specifications

- Operating Frequency: 60 ops/min
- Insulation Resistance : >100 MΩ@500 V dc
- Contact Resistance: <25 mΩ (initial)
- Rated Current/Voltage: 20 A 125 V ac/250 V ac/480 V ac 1.5HP/125 V ac,2HP/250 VA
- Dielectric Strength: 1000 V ac for 1 min between current carrying parts
2500 V ac for 1 min between non-current carrying parts
- Service Life: Mechanically 1 x 10⁶ Electrically 5 x 10⁵
- Operating Temperature : -20~+80°C (-4~176°F)
- Degree of Protection: IP68
- Size (L x W x H): IP68 228 x 157 x 140 mm