


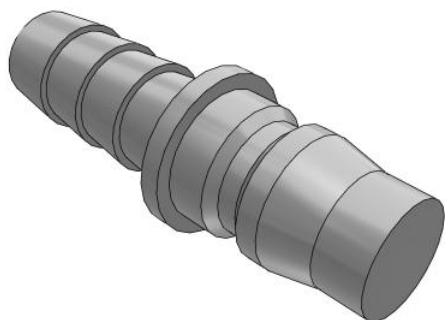

KK130P-*B, S-Couplers, Barb Fitting KK130P-11B

Datasheet


General series information

- Barb Fitting.
- Hose Nominal: 1/4, 3/8, 1/2.

Standard specifications

Hose Nominal	ø9 (ø3/8")
Pressure medium	Air
Maximum operating pressure	1.5 MPa
Minimum operating pressure	0 MPa
Proof pressure	2 MPa
Maximum ambient temperature	80 °C
Minimum ambient temperature	-20 °C (No freezing)
Sealing principle	Male thread with sealant
Plating	Sleeve: Electroless nickel plated Other external metal parts: Zinc chromated
Weight	0.020 Kg

Dimensions

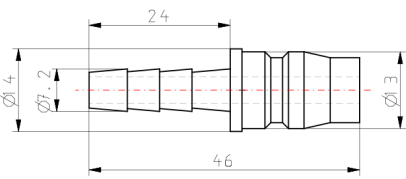

Additional information

Catalogue

[KK130-B_EU.pdf](#)