

PC/USB KVM Switch SERVIS™ Series 2-Port FS-102AT and ATU

Access 2 PCs from 1 console (KB, Video Monitor, Mouse) by using this KVM Switch, and get a dedicated USB Hub Port for each PC.

■ FEATURES

- **Space saving**
You save space by eliminating an unnecessary keyboard, monitor and mouse.
- **Power Saving**
Only one monitor is needed, reducing power and air conditioning requirements.
- **Flexibility**
Up to 4 PCs are supported - by adding a second KVM Switch an additional 2 PCs are switched
- **Easy to Use**
Power is supplied from the KB/mouse port of the PC. For USB devices requiring it, an AC adapter is included
- **Stable switching**
Dedicated Microcontroller for each port ensures no service interruptions when switching
- **Supports PS/2 Keyboard and Mouse**
English, European and Japanese languages (101 to 109 keys) 2/3 button mouse, scrolling mouse



KVM Switch/PC/USB - FS-102 Series - PC/USB Interface


■ SPECIFICATIONS

Items		Specifications	
Model		FS-102AT	FS-102ATU
Supported Machines		PC / DOS/V compatible	PC DOS/V compatible with USB Port; Mac with USB Port
Ports		2, expandable to 4	
Selection Method		Front panel button, Keyboard (hot key)	
LED Indication		Power 2x, Select 2x, Low Power 1x	
Console Port	Keyboard	PS/2 Mini DIN 6P female, front panel, back panel	
	Mouse	PS/2 Mini DIN 6P female, front panel, back panel	
	Monitor	Mini D-SUB 15 female x 1	
PC Port	Keyboard/Mouse	PS/2 Mini DIN 6P female	
	Monitor	Mini D-SUB 15 female x 1	
	USB	N/A	Series "B" female, back panel
HUB port		N/A	Series "A" female, 500mA/port front panel
Daisy Chain Port		Daisy Chain connector 14P female	
Monitor Resolution / Bandwidth		1600 x 1200 / 200MHz	
Power Supply		5VDC±5% supplied from KB and Mouse port of PC	
External Power, dedicated AC adaptor		5VDC±5% supplied from 5VDC connector	
Current Consumption		100mA maximum from host PC	
Operation temperature/humidity		0 - 40° C, 90%RH	
Storage Temperature		-20° C to +60° C	
Structure		Molded plastic enclosure	
Dimensions (mm)/ Weight (g)		148W x 115D x 39.4H / 380 g	
Included cables		Cable Set 1.8m x2	Cable Set (1.8 m x2; 2 USB cables, AC adaptor (5VDC, 1A))
Optional cables	KB/Mouse Cable (3m)	FS-C103A	
	Daisy Chain Cable	FS-101D	
	USB Host Cable (3m)		FS-103U


KVM Switch/PC/USB - FS-102 Series - PC/USB Interface

■ CONNECTION SCHEMES

Single Unit
Daisy Chain

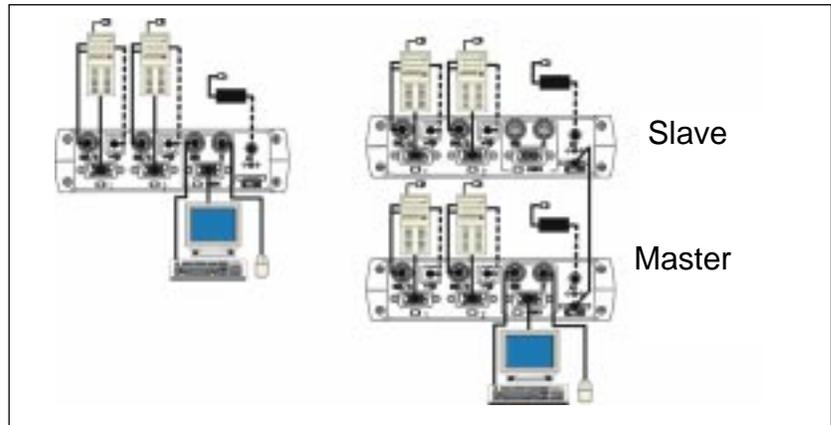

■ FUNCTIONAL DESCRIPTION

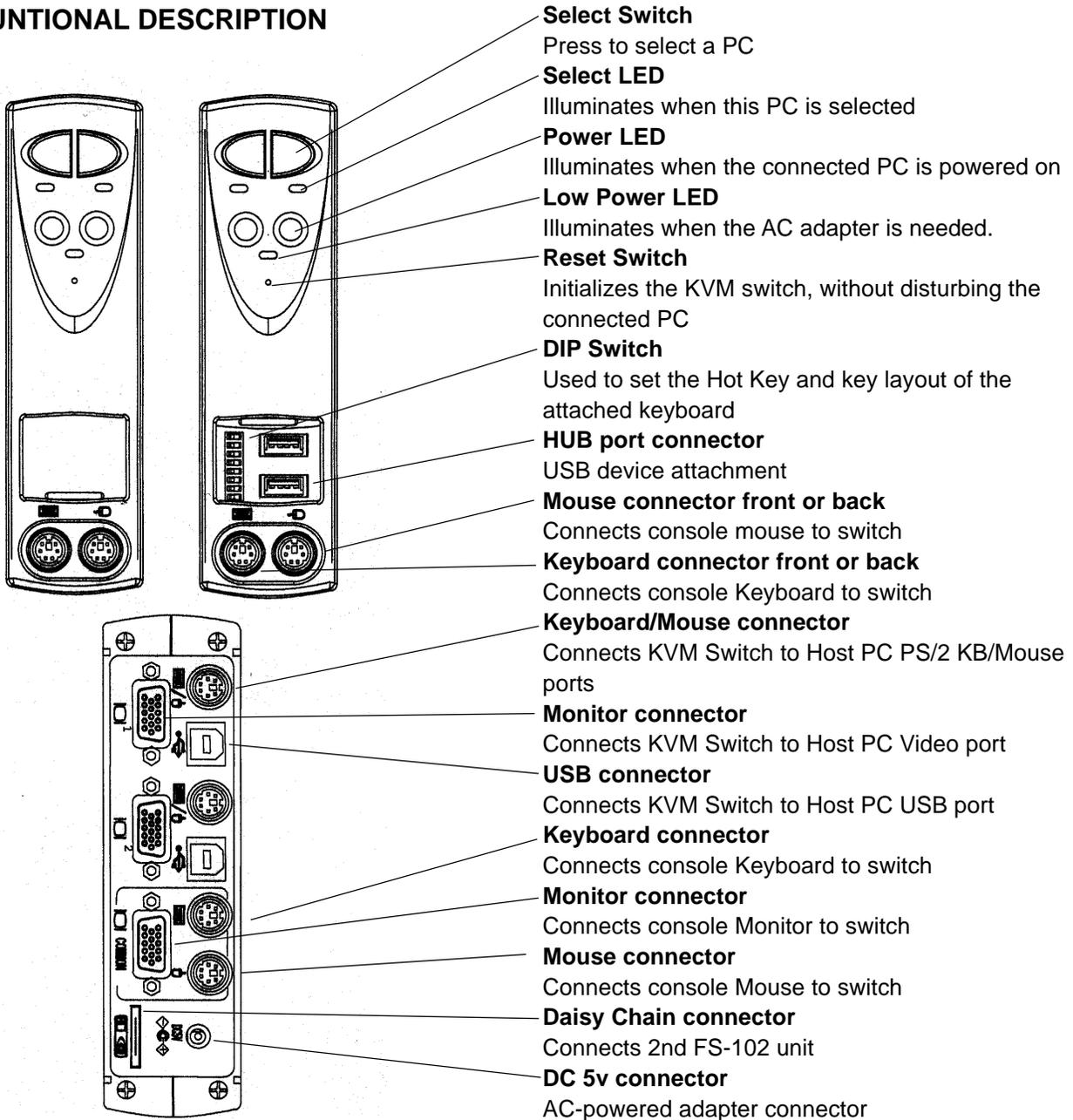

KVM Switch/PC/USB - FS-102 Series - PC/USB Interface

Fujitsu Components International Headquarter Offices

Japan

Fujitsu Component Limited
Gotanda-Chuo Building
3-5, Higashigotanda 2-chome, Shinagawa-ku
Tokyo 141, Japan
Tel: (81-3) 5449-7010
Fax: (81-3) 5449-2626
Email: promothq@ft.ed.fujitsu.com
Web: www.fcl.fujitsu.com

North and South America

Fujitsu Components America, Inc.
250 E. Caribbean Drive
Sunnyvale, CA 94089 U.S.A.
Tel: (1-408) 745-4900
Fax: (1-408) 745-4970
Email: marcom@fcai.fujitsu.com
Web: www.fcai.fujitsu.com

Europe

Fujitsu Components Europe B.V.
Diamantlaan 25
2132 WV Hoofddorp
Netherlands
Tel: (31-23) 5560910
Fax: (31-23) 5560950
Email: info.marketing@fceu.fujitsu.com
Web: www.fceu.fujitsu.com

Asia Pacific

Fujitsu Components Asia Ltd.
102E Pasir Panjang Road
#04-01 Citilink Warehouse Complex
Singapore 118529
Tel: (65) 375-8560
Fax: (65) 273-3021
Email: fcal@fcal.fujitsu.com
www.fcal.fujitsu.com

© 2001 Fujitsu Components America, Inc. All company and product names are trademarks or registered trademarks of their respective owners. Rev. 09/2001