




MULTIBAND 304 Stainless Steel:- 11mm Wide

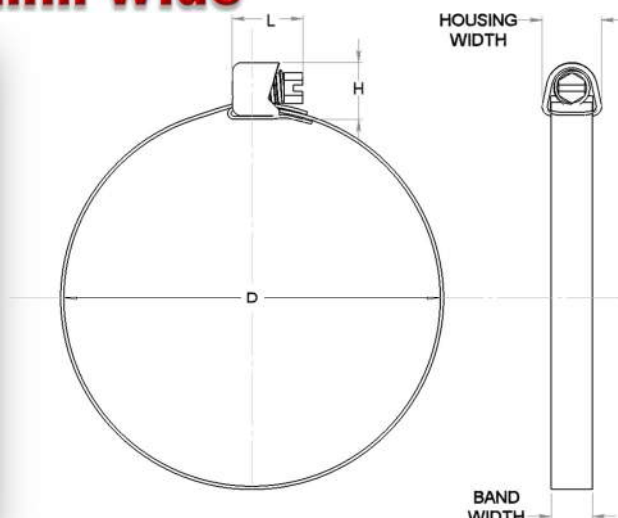

Range	Adjustment mm	Band Width mm	Band Thickness mm	Recommended Torque Nm	Maximum Torque Nm	Maximum Pressure PSI	Range
MB11SS	Cut to length	11.0	0.80	3.4	4.5	n/a	MB11SS

Component Parts for MB11SS:-



Banding in dispensers of 10m

Part No. **MB1801**

- 11mm wide
- 10 metre roll
- 304 Stainless steel



Banding in dispensers of 30m

Part No. **MB1802**

- 11mm wide
- 30 metre roll
- 304 Stainless steel



Handy Pack

Part No. **MB1806**

- 11mm wide
- 10 metre roll
- 25 solid housings/screws
- 304 Stainless steel



Housings/screws for use with 11mm Multiband

Part No. **MB1803**

- Solid housing
- 7mm A/F hexagonal screw
- Box of 25 sets
- 304 Stainless steel



Captive housings/screws for use with 11mm Multiband

Part No. **MB1805**

- 7mm A/F hexagonal screw
- Box of 25 sets
- 304 Stainless steel



Housings/Allen screws for use with 11mm Multiband

Part No. **MB1804**

- Solid housing
- 5/16" recess hexagonal key slot
- Box of 25 sets
- 304 Stainless steel

Corrosion Resistance: 1000 hours NSS Test

Fastening: 7mm A/F screw

Industry Recommendations:-



Pocket Pack

Part No. **MB1807**

- 11mm wide
- 3 metre roll
- 8 solid housings/screws
- 304 Stainless Steel

304 Stainless Steel