

# A-SEW-32-P-W - Flat gasket



1411285

<https://www.phoenixcontact.com/gb/products/1411285>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Flat gasket, for threads M32, color: white



## Commercial data

Item number	1411285
Packing unit	200 pc
Minimum order quantity	200 pc
Sales key	AF7DZX
Product key	AF7DZX
Catalog page	Page 658 (C-3-2019)
GTIN	4046356924160
Weight per piece (including packing)	1.918 g
Weight per piece (excluding packing)	3 g
Customs tariff number	39269097
Country of origin	GB

# A-SEW-32-P-W - Flat gasket



1411285


<https://www.phoenixcontact.com/gb/products/1411285>

## Technical data

### Product properties

Product type	Seal
Manufacturer	CMP
Manufacturer Designation	32MM WHITE NYLON ETS 2MM THICK
Manufacturer product number	32ETS2
Thread type	M32

### Dimensions

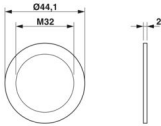Dimensional drawing	
Height	2 mm
Thread type connection side	M32

### Internal dimensions

Internal diameter	32 mm
-------------------	-------

### Material specifications

Material	Nylon
----------	-------

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-60 °C ... 130 °C
---------------------------------	-------------------

### Mounting

Assembly note	for A-EXSH-M...-68L-... / G-ESSWU-M... / G-EDSWU-M... / G-ESS-M...
---------------	--

# A-SEW-32-P-W - Flat gasket


1411285

<https://www.phoenixcontact.com/gb/products/1411285>



## Drawings

Dimensional drawing

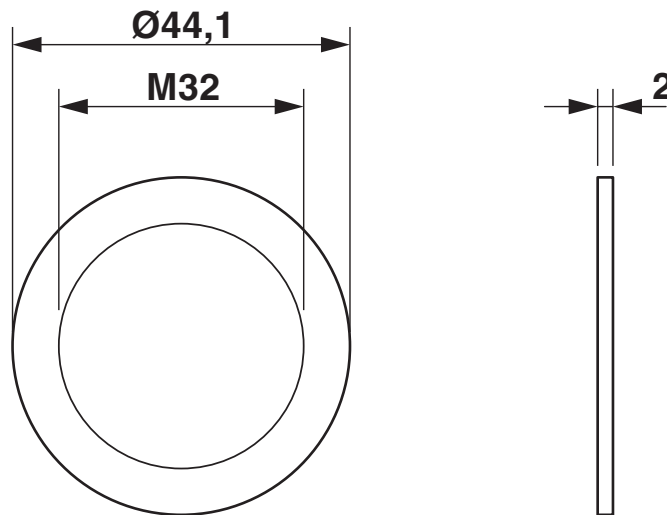

Dimensional drawing

# A-SEW-32-P-W - Flat gasket



1411285

<https://www.phoenixcontact.com/gb/products/1411285>

## Classifications

### ECLASS

ECLASS-13.0	27430319
-------------	----------

### ETIM

ETIM 9.0	EC001181
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# A-SEW-32-P-W - Flat gasket



1411285

<https://www.phoenixcontact.com/gb/products/1411285>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	21245208-e2d5-4bc7-a1df-3cb0873e7d98

### EF3.0 Climate Change

CO2e kg	0.099 kg CO2e
---------	---------------

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)