

## Model: NP 121

### Inclinometer

**Rotatable** plexiglass **circular disk**.

Dims. 130 x 130 mm

Barrel-shaped, unbreakable acrylic block-vial.

3 different **measure values** on the circular scale:

1. angular degrees of  $4 \times 90^\circ = 360^\circ$ ,  
by request in gons (grades = 1/100 of a right angle)
2. gradients 0-100%
3. slope and inclination ratios


### Target group:

Craftsmen

### Range of applications:

Used independently or as attachment mounted on a measuring or setting rod (attachable construction).

Model	Dims.
NP 121	13 x 13 cm
NP 121 S* (attachable)	13 x 13 cm

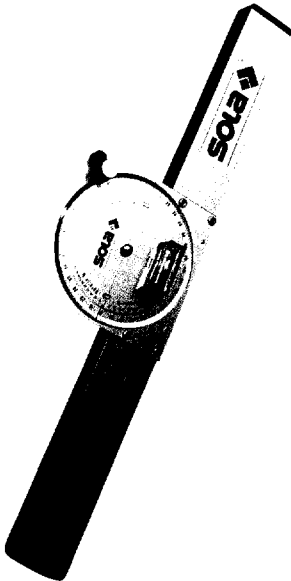

## Model: APN

### Inclinometer

NP 121,  
mounted on an **aluminium** rectangular **box section profile**.

Dims. 50 x 23 mm


Gold anodized surface.

The same measure values as NP 121.

### Target group:

Carpenters, joiners and builders.

Model	Length
APN 60	60 cm
APN 100	100 cm

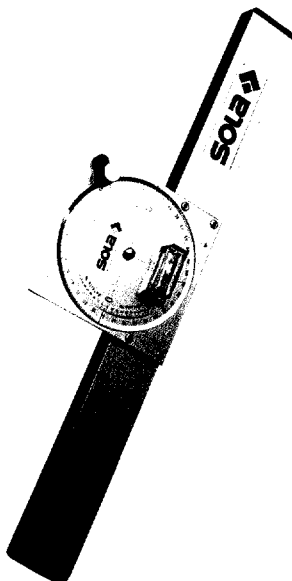

## Model: NAM

### Inclinometer

NP 121

mounted on an **aluminium** rectangular **box section profile with strong magnets**.

Dims. 50 x 23 mm

Gold anodized surface.

The same measure values as NP 121.

- length 13 cm 1 magnet  
length 20 cm 2 magnets  
length 50 cm 2 magnets

### Target group:

Locksmiths and metal workers.

Model	Length
NAM 13	13 cm
NAM 20	20 cm
NAM 50	50 cm

