



COUPLING

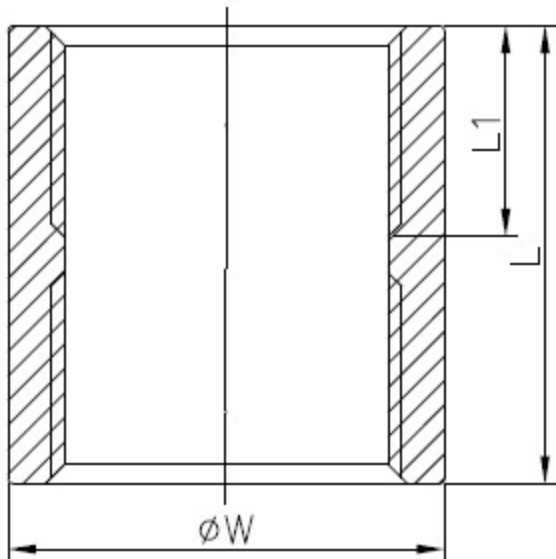

NPT

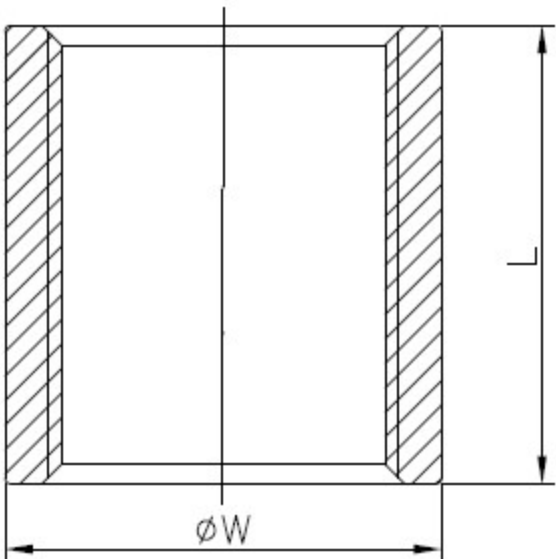

PS

SIZE	1/8"		1/4"		3/8"		1/2"		3/4"		1"		1-1/4"		1-1/2"		2"		2-1/2" (NPT)		2-1/2" (PS)		3"		4"		5" (NPT)		6" (NPT)	
	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in
L	20	0.79	25	0.98	25	0.98	33	1.3	35	1.38	41	1.61	46.5	1.83	46	1.81	54.5	2.15	65	2.56	65	2.56	69	2.72	79	3.11	90	3.54	100	3.94
L1	8	0.31	10.4	0.41	11	0.43	15.1	0.59	15	0.59	17.4	0.69	19.8	0.78	20	0.79	23.9	0.94	28.7	1.13	-	-	29.7	1.17	33.2	1.31	36	1.42	39	1.54
W	13.5	0.53	18	0.71	21.5	0.85	26	1.02	31.5	1.24	38.5	1.52	47.5	1.87	54	2.13	66.5	2.62	80	3.15	83	3.27	95	3.74	122	4.8	160	6.3	186.5	7.34
Weight	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb	kg	lb
	0.012	0.026	0.026	0.057	0.03	0.066	0.056	0.123	0.071	0.157	0.12	0.265	0.187	0.412	0.202	0.445	0.337	0.743	0.639	1.409	0.639	1.409	0.754	1.662	1.17	2.579	3.796	8.369	4.864	10.723

△ Tolerance:±1.0mm(1/8"~2")
±1.5mm(2-1/2"~6")