


SylRadiance TW 1500LM SST

Item No: 0090097




YourHome

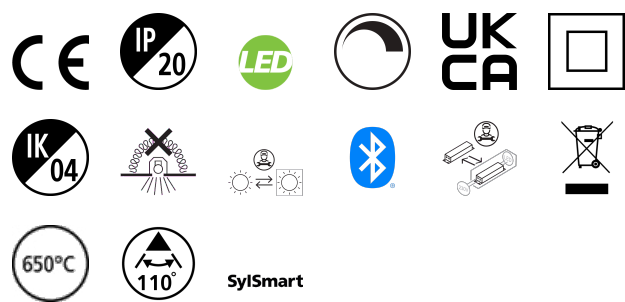

Modern and versatile smart ceiling luminaire with adjustable tuneable white light and captivating RGB halo ring, creating a personalised ambiance for any occasion. Works effortlessly with SylSmart App, SylRemote and Alexa, Google Assistant and Siri shortcuts for seamless control and convenience. Customise the perfect lighting for any mood with adjustable colour temperature (2700K-6500K), from warm and cosy to bright and refreshing. Adjust brightness from 1% to 100% with wireless dimming function for the ideal lighting experience. Instantly transform your home with pre-set scenes for different moods and occasions using the SylSmart Home APP or SylRemote.

Technical Assets

Dimensions (mm)

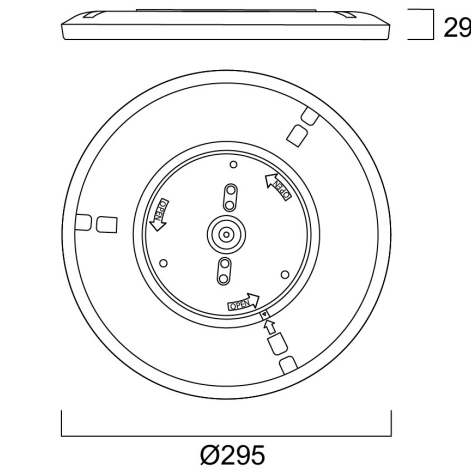

Photometrics

SylRadiance TW 1500LM SST

Item No: 0090097



General data

Product name	SylRadiance TW 1500LM SST
Technology	LED
Cap/Base	N/A
Housing	Composite material
Mount	Ceiling surface mounting
General application	Residential & Consumer
Operating temperature range (°C)	-20°C...+40°C
ETIM Class	EC002892
E-number FI	4279566
Warranty	3 years

Optical data

Fixture luminous flux (lm)	1500
Luminaire efficacy (lm/W)	83
Correlated colour temperature (k)	4000
Light colour	Tuneable White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	110
Distribution type	None
Photobiological Risk Group	RG0

Electrical data

Total power consumption (W)	22
Current (A)	0.1
Primary Supply/Product voltage - min (V)	220.0
Primary Supply/Product voltage - max (V)	240.0
Lamp power factor	0.7
THD (at 230 V, 50 Hz, full load, at 100% dimming level) ≤ xx.x %	30
Electrical protection	Class II
Control gear type	Not required
Dimmable	Yes
Dimming method	SylSmart SST
Inrush Current (A)	16
Inrush Duration (µs)	140
Energy Efficiency Class (A->G) of contained light source	D
Nominal Frequency (Hz)	50/60Hz
Max. products per 10A C Breaker	62
Max. products per 16A C Breaker	24
Max. products per 16A B Breaker	14
Connectable conductor cross section - Max (mm²)	1.5

Lifetime data

Lifespan L70 B50	50000
------------------	-------

Physical data

Housing colour	White
IP rating	IP20
IK rating	IK04
Diffuser finish	Diffuse
Diffuser material	PMMA Acrylic
Nominal Product Height (mm)	28.5
Nominal Product Diameter (mm)	295
Weight (kg)	0.68

SylRadiance TW 1500LM SST

Item No: 0090097



Packaging

Product EAN number	5410288900971
Packaging single length / height (cm)	31.5
Packaging single width (cm)	32.5
Packaging single depth (cm)	5.8
DUN14 (inner)	15410288900978
Units per outer package	6
Packaging outer length / height (cm)	37.6
Packaging outer width (cm)	32.8
Packaging outer depth (cm)	34.3

Safety data

Glow Wire Test (°C)	650
Optimal operating condition (°C)	-20-40