


## Rectangular Alcomax Magnet

Part Number :RSH01

### Product Data Sheet

#### PICTURE

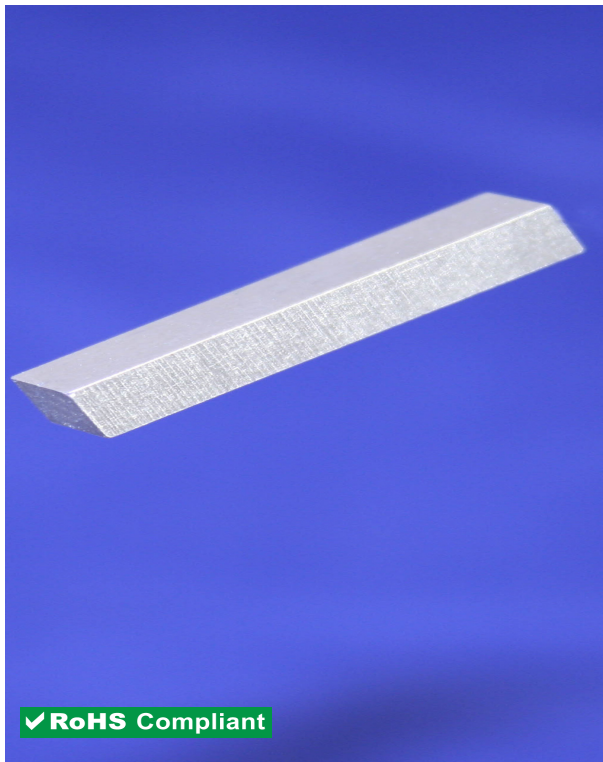

✓ RoHS Compliant

#### DIMENSIONS



Drawings not to scale  
All dimensions in mm nominal

#### SPECIFICATION

Material		Alcomax
Size	Length mm	12.7
	Width mm	1.59
	Height mm	3.18
Gauss strength / surface		140
Temperature	Max Celsius	550°

#### Applications Include

- Access control.
- Appliance switching.
- Control panel.
- Proximity switching.

#### Options

- Neodymium grades up to 52 available.
- Cylindrical, ring, rod and hosued magnets available.
- Custom magnets from Neodymium, Samarium Cobalt, Alcomax. Plated, unplated, powder coated.
- If you do not see what you need, just ask, as there is a strong possibility we can do it !

#### Did you know we also sell?



#### Rev. No.

#### Revision Note

#### Date

#### Signature

1

Datasheet

26-04-16

ML



ISO 9001:2008  
Certificate No. FM21080

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone : +44 (0)1255 862236

[www.comus-intl.com](http://www.comus-intl.com)

Fax: +44 (0)1255 862014

©2016 Copyright Comus Europe Ltd, Unit 7, Rice Bridge Industrial Estate, Thorpe - Le - Soken, Essex, CO16 0HL, ENGLAND.  
USA: Comus International: +1 973 777 6900, Belgium: Comus Belgium BVBA: +32 (0)12 390400