


NATR17-PP

Galet de roulement

Yoke type track rollers NATR...-PP-A, single row needle roller bearings with particularly thick-walled outer ring, needle roller and cage assembly and an inner ring, axial guidance of outer ring is provided by the plastic axial plain washers and contact washers, three-stage sealing by plastic axial plain washer on both sides

Information technique

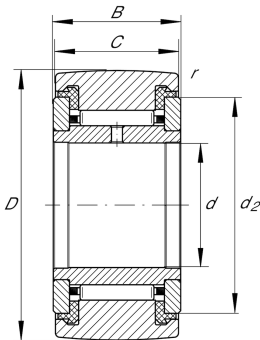

Votre alternative produit actuelle

joint	PP	Joint frottant des deux côtés
profile bague extérieure	IOP	Optimized INA-profile
dispositif de lubrification	IR	Via inner ring

dimensions principale & données de performance

d	17 mm	Alésage
D	40 mm	Diamètre extérieur
B	21 mm	Largeur, bague intérieure
C _{r w}	10.900 N	Charge dyn. de base, radiale
C _{0r w}	16.000 N	Charge stat. de base, radiale
C _{ur w}	2.130 N	Limite à la fatigue, radiale
n _{D G}	2.900 1/min	Vitesse pour une lubrification à la graisse
F _{0r per}	16.000 N	Charge radiale statique admissible
F _{r per}	16.000 N	Charge radial dynamique admissible sur bague extérieure
≈m	0,137 kg	Poids

Dimensions

C	20 mm	Largeur, bague extérieure
d ₂	31,5 mm	Diamètre extérieur rondelle de butée
r _{min}	1 mm	Dimension minimum de chanfrein



Caractéristiques



Effort radial



Lubrification à vie, sans entretien



Lubrification à la graisse



Étanche des 2 côtés