

Actuator

704.022.4

Distribution by
Rs-online<https://rs-online.eao.com/p/704.022.4>

Your product:



704.022.4 Actuator

FRONT

Front dimension: Ø 29 mm

Front form: Round

MOUNTING

Design: Raised

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens cap colour: Yellow

Lens cap material: Plastic

Lens cap optical effect: translucent

Marking cap colour: White

Marking cap optics: translucent

ELECTRICAL CHARACTERISTICS

Standards: The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

MECHANICAL CHARACTERISTIC

Terminal: Screw terminal

Weight: 0.025 kg

AMBIENT CONDITION


IP Protection:	IP65 front side
Operating temperature:	– 40 °C ... + 55 °C
Storage temperature:	– 40 °C ... + 85 °C

CERTIFICATE


REACH:	REACH compliant
RoHS:	RoHS compliant

OTHER

Short Description:	Actuator, Ø 29 mm, Round, Screw terminal
Housing colour:	Grey
Housing material:	Plastic
Product attributes:	Filament lamp 130 V, max. 2.6 W with integrated series resistor 230/130 V
Wiring diagrams:	

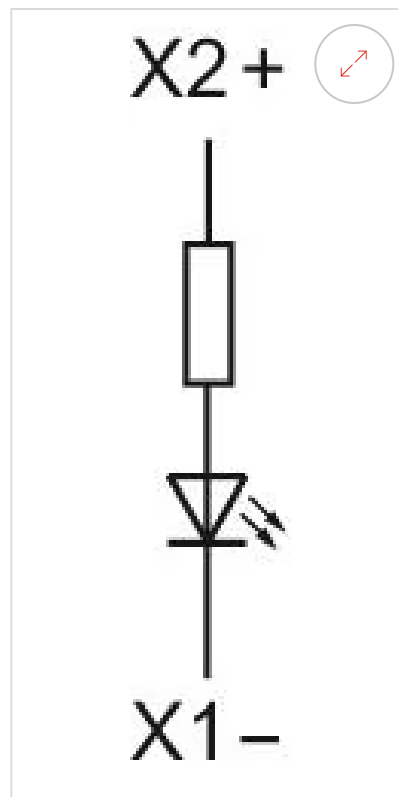

Mounting cut-outs:

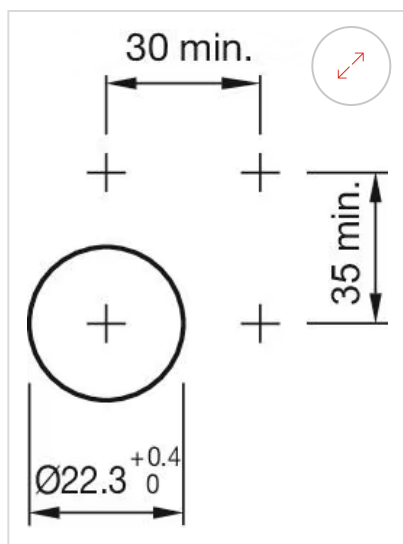

Dimension drawings:

