





**LED PL Glass TC-TEL GX24q 4P 10.5W (32W) 1800lm 840 AC**

Article number: 146762

BAI LED PL Glass GX24q 4-pins TC-TEL 10.5W (32W) 4000K Frosted 1800lm 230V-240V 360° 49x155mm Temp. -20°C +40°C LED-lamp Alt PLT Dulux T/E

The LED PL Glass GX24 (4-pin) TC-TEL lamps are replacements for the often used compact fluorescent lamps without integrated ballast. PL stands for Public as these lamps are mainly used in public spaces, corridors, offices and as orientation lighting. This PL LED series has the same shape and size as its fluorescent predecessors. In addition, just like their predecessor, they are made of glass, which ensures the same uniform light image. They are therefore a 1-on-1 sustainable replacements. Connect directly to mains voltage (AC). Not for use with Electronic Ballast (HF/ECG), disconnect ballast before use! Always read the manual carefully before installation.

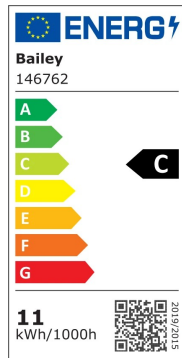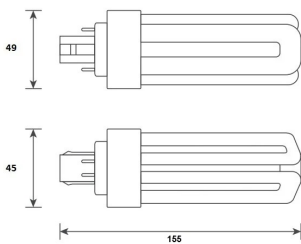

**General ETIM properties**

|               |  |
|---------------|--|
| ETIM group    | Lamps  |
| ETIM class    | LED-lamp/Multi-LED                                     |
| Name          | LED PL Glass TC-TEL GX24q 4P 10.5W (32W) 1800lm 840 AC |
| Brand         | Bailey   |
| Productseries | LED PL Glass   |
| Producttype   | GX24q 4P AC  |

## ETIM specifications

|   |                           |
|---|---------------------------|
| Socket  | Other                     |
| Luminous flux [lm]                              | 1800 - 1800               |
| Nominal voltage [V]                             | 220 - 240                 |
| Lamp power [W]                                  | 10.5 - 10.5               |
| Colour temperature [K]                          | 4000 - 4000               |
| Diameter [mm]                                   | 49                        |
| Length [mm]                                     | 155                       |
| Dimmable  | No                        |
| Lamp shape                                      | Tube, single-ended        |
| Beam angle [°]                                  | 360 - 360                 |
| Colour  | White                     |
| Type of glass/cover                             | Opal                      |
| Lamp designation                                | Other                     |
| Colour rendering index CRI                      | 80-89                     |
| Voltage type                                    | AC                        |
| Filament lamp                                   | No                        |
| Rated luminous flux according to IEC 62612 [lm] | 1800                      |
| Power factor                                    | 0.5                       |
| Lamp efficacy [lm/W]                            | 171                       |
| Nominal current [mA]                            | 86 - 86                   |
| Colour of light according to EN 12464-1         | Neutral white 3300-5300 K |
| Housing colour                                  | White                     |
| Average nominal lifetime [h]                    | 30000                     |
| Degree of protection (IP)                       | IP20                      |
| Colour consistency (McAdam ellipse)             | SDCM5                     |
| Min. number of switching cycles                 | 15000                     |
| Weighted energy consumption in 1000 hours [kWh] | 11                        |
| Remote operation possible                       | No                        |
| With movement sensor                            | No                        |
| With remote control                             | No                        |
| Photobiological safety according to EN 62471    | RG0                       |
| Compatible with Apple HomeKit                   | No                        |
| Compatible with Google Assistant                | No                        |
| Compatible with Amazon Alexa                    | No                        |
| IFTTT support available                         | No                        |
| Suitable for electronic ballast                 | No                        |
| Suitable for magnetic ballast                   | Yes                       |
| Dimming phase cut-off (trailing edge)           | No                        |
| Dimming phase cut-on (leading edge)             | No                        |
| Dimming Touch and Dim                           | No                        |
| Dimming Zigbee                                  | No                        |

|  |       |
|--|-------|
| Dimming Bluetooth  | No    |
| Dimming Wi-Fi  | No    |
| Energy efficiency class according to EU regulation 2019/2015 | C     |
| With twilight switch   | No    |
| Material of light bulb                                       | Glass |

### Alternative articles



145931

LED PL TC-TEL GX24q-3 4P  
16W (32W) 1800lm 840  
ECG+AC