

# PML50 Series

## 0.688" (17.5mm) Low Profile LED FlexVolt™ Panel Mount Indicator



### Mounting Hole

[0.688" \(17.5mm\)](#)

### Terminal

[24 AWG 5.5" Wire Leads](#)

### Lens

[Low Profile Clear Lens.](#)

### Color

[Red, Green, White, Blue, Yellow and bi-color: red/green](#)

### Voltage

[FlexVolt: 5-28 volt DC circuits](#)

### IP

[IP67 \(watertight\)](#)

### Compliance

[RoHS, REACH](#)

The PML50 Series panel mount indicator with FlexVolt™ technology feature built-in ultra bright LED with a unique optical low profile lens.

Provide uniform illumination and are designed for applications that require accurate recognition, regardless of external conditions. Achieve full brightness in microseconds - even in daylight viewing conditions.

Designed for reliability in harsh environments, PML50 are built for unique performance and durability requirements necessary for a wide range of applications.

The ruggedized PML50 Series FlexVolt™ indicator can be used with voltage ranging from 5V to 28V DC Circuits which reduces inventory cost and opens up unlimited design opportunities.


Available in five single colors: red, green, white, blue or yellow and in bi-color: red/green all offered with a clear lens for increased contrast between on and off.

### PML50 Series

Part Number	Voltage	Color	Order Qty.	Special Price Ea.
PML50RFVW	Flex Voltage 5-28 V DC	Red	100	\$4.788
PML50WFVW	Flex Voltage 5-28 V DC	White	100	\$4.788
PML50GFVW	Flex Voltage 5-28 V DC	Green	100	\$4.788
PML50BFVW	Flex Voltage 5-28 V DC	Blue	100	\$4.788
PML50YFVW	Flex Voltage 5-28 V DC	Yellow	100	\$4.788
PML50RGFVW	Flex Voltage 5-28 V DC	Red/Green	100	\$4.788

### Quote Number

When placing an order please reference quote number:	<b>NPI50PM2017</b>
--	--------------------

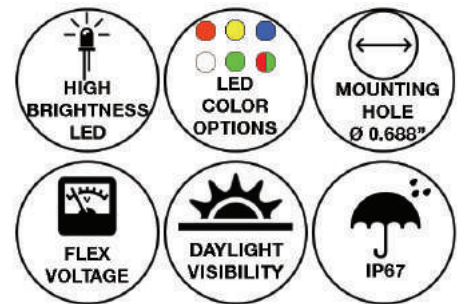

### PML50 Series

When your equipment demands accurate recognition regardless of external conditions