



Brand of NTN corporation

Technical data

USPP207

Bearing units




Sheet metal housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US207G2, PP207

VISUAL (S)

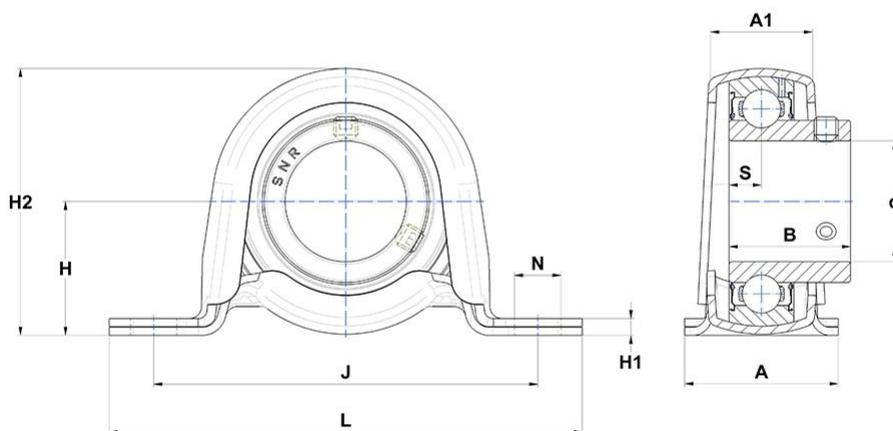

PRODUCT DEFINITION

Brand	SNR
A - Housing width	41 mm
A1 - Housing top width	28,4 mm
B - Width of Inner Ring	32 mm
d - Shaft diameter	35 mm
H - Distance mounting base to centerline spheric. seating diam.	39,7 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

H1 - Housing foot height	4,4 mm
H2 - Housing height	77,5 mm
J - Mounting holes distance	106 mm
L - Housing length	128,6 mm
N - Mounting hole dimension	11 mm
S - Distance front side/bearing centre	8,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,64 kg
Recommended tightening torque for set screw	5.5 N-m

