




105-70-1

1/4" Pear Type Reversible Ratchets

PRODUCT DETAILS

- 72 teeth/5° action angle
- Quick-release function
- Quick, easy direction change lever on wrench head
- Slim head for narrow places
- Rounded shapes and highly polished surfaces with no sharp points

- Comfortable non-slip two-component handle with hanging hole for easy storage
- Made of high-performance alloy steel, precision forged and heat treated for optimum durability
- Retail packed on an anti-theft plastic card
- Standards: ISO 3315/1174-2, DIN 3122/3120

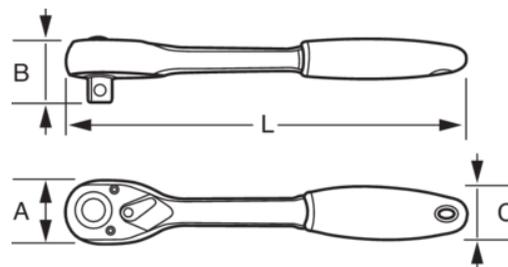

PRODUCT ATTRIBUTES

Product				A	B	C	L	
105-70-1	1/4 in	5 °	72	28 mm	25 mm	23 mm	152 mm	151 g