



Datasheet

ENGLISH

# RS PRO Pre-Wired Male Connector, 3 Contacts, Panel Mount M8. IP67

RS Stock No: 201-7168


## General Specification

Rated Operational Voltage	60 V
Current Rating	3A
Insulation Resistance	$\geq 100 \text{ M}\Omega$
Temperature Range	-25°C ... +75°C
Degree of Protection	IP67
Mounting	Front (M8 x 0.5)



## Material Specification


Housing Material	Brass Ni Plated
Contact	Cu-Zn
Contact Plating	Gold Flash
Contact Carrier	Nylon 66
O-Ring	Neoprene
Pole	3
Clamp Nut	M8 x 0.5

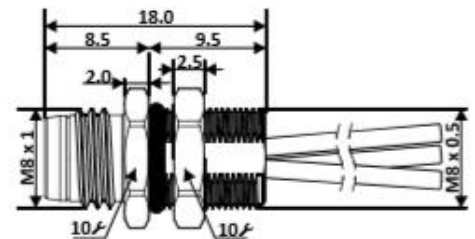

## Cable Specification

Cross Section of Wire	0.25 sq. mm
Termination	Partially Stripped
Cable length	500 mm

## Pin Assignment

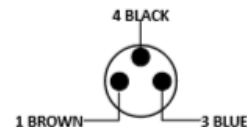

## Recommended Panel Cutout

