
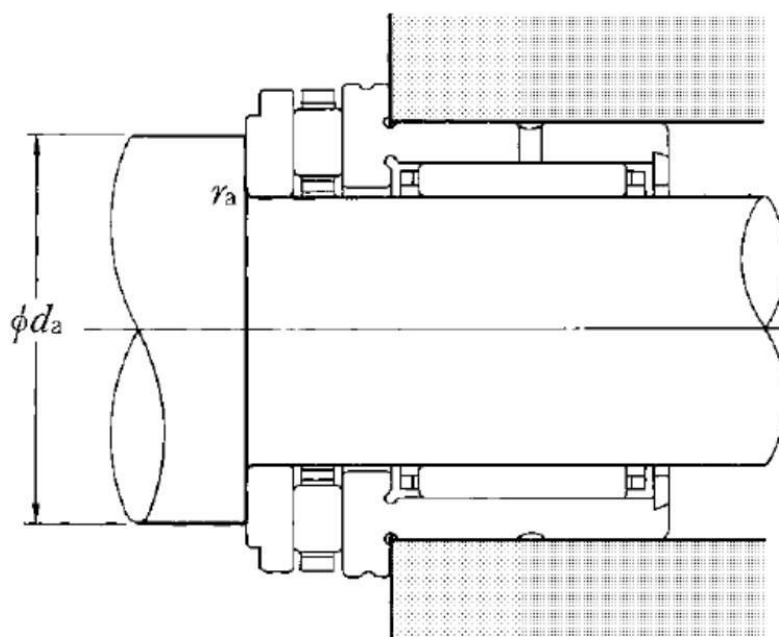


VISUAL (S)

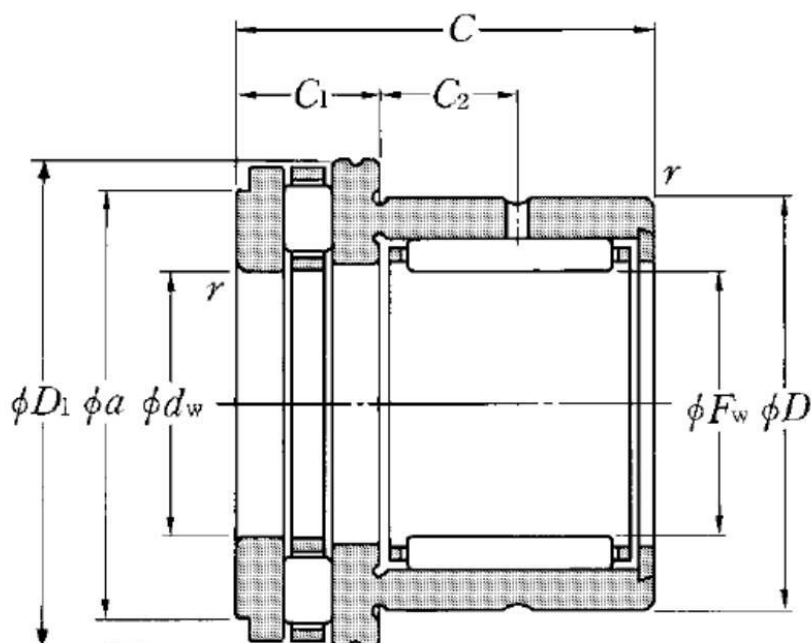

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	30 mm
dw - Shaft washer bore diameter	30 mm
D - External diameter	42 mm
D1 - Outer diameter of washer	47 mm
C - Width of bearing, drawn cup or outer ring	30 mm
C1 - Thrust bearing height	11 mm
C2 - Hole location	9,5 mm
a - Thrust bearing support diameter	42,7 mm
rs - Min fillet radius	0,6 mm
Lubrication hole on outer ring	Oui/Yes
Precision class	P0
Mass	0,162 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	22300000 mN
Ca - Dynamic axial load rating	27800000 mN
C0r - Static load rating	39500000 mN
C0a - Static axial load rating	72500000 mN
N lim - Grease lubrication limit speed	9000 °/s
N lim - Oil lubrication limit speed	36000 °/s
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	393,15 °K



ABUTMENT	
da min - Min shoulder diameter IR	44 mm
ras max - Max shaft & housing fillet radius	0,6 mm

