


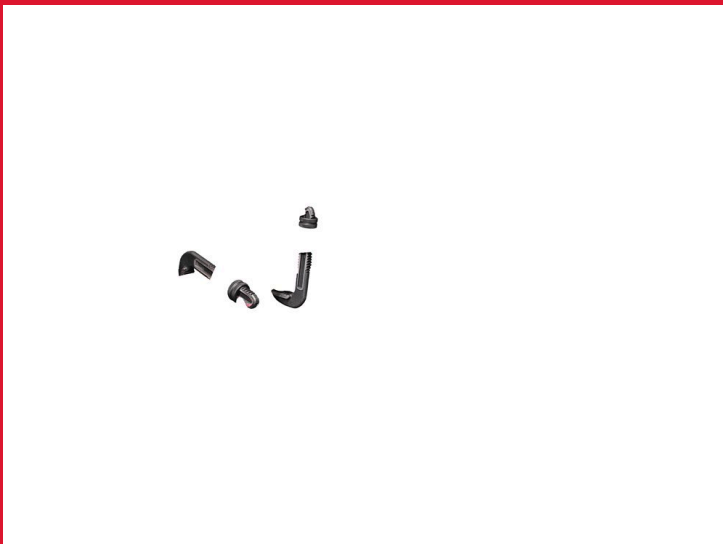

# Adaptable Pipe Wrench

## CHEATER - ADAPTABLE PIPE WRENCH

- 3 handle design - 10"/ 250 mm mode for tight spaces, 18"/ 450 mm mode for general purpose, 24"/ 600 mm mode for maximum leverage and reach.
- Overbite jaw for secure grip on pipes and fittings.
- Dual coil springs for maximum durability and tool life.
- Ergonomic handle for maximum comfort, won't dig into the palm.
- Ergonomic hook jaw design - for easy detachment from the workpiece.
- Hardened jaws for increased durability and better grip.
- Lanyard hole.



|                                      |             |
|--------------------------------------|-------------|
| Article Number                       | 48227314    |
| Jaw opening capacity for pipe (inch) | 2.5         |
| Jaw opening capacity for pipe (mm)   | 63          |
| Pack quantity                        | 1           |
| Total length (inch)                  | 10/18/24    |
| Total length (mm)                    | 250/450/600 |
| Weight (g)                           | 3243        |