


FEATURES

- **Nylon Material:** Offers durability and resistance to wear and tear
- **Non-Releasable Design:** Ensures a secure and permanent fastening
- **UV Resistant:** Suitable for outdoor use, resisting degradation from sunlight
- **Tensile Strength of 22 kg:** Provides strong and reliable cable bundling
- **Operating Temperature Range -40°C to 85°C:** Suitable for diverse environmental conditions
- **RoHS Compliant:** Meets safety and environmental standards
- **UL 94HB Fire Behaviour:** Provides basic protection against fire hazards

RS PRO Nylon Cable Tie, 385mm Length

RS Stock No: 656-101

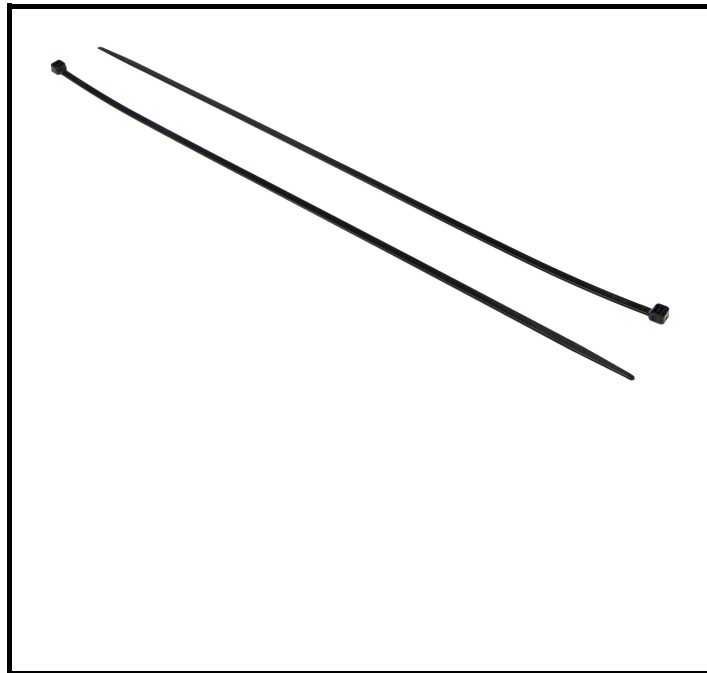

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS PRO Nylon Cable Tie is designed for secure and reliable bundling of cables and wires. With a length of 385 mm, it is ideal for managing larger cable bundles, ensuring a neat and organised setup. Its robust construction provides excellent tensile strength, making it suitable for various industrial applications.

General Specifications

Colour	Black
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	22 kg

Protection Category

Fire Behaviour	UL 94HB
UV Resistant	Yes

Mechanical Specifications

Length	385 mm
Material	Nylon
Maximum Bundle Diameter	110 mm
Width	4.8 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
Minimum Operating Temperature	-40 °C

Approvals

Standards/Approvals	RoHS, UL94HB
---------------------	--------------

