


Geberit Mapress Copper elbow adaptor 90° with male thread



Example image

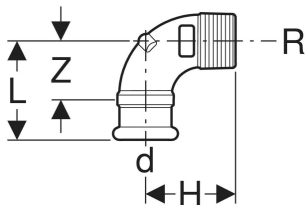

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For service water and process water
- For compressed air (oil purity class 0–3)

- For negative pressure
- For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding

- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed

TECHNICAL DATA

Product material Gunmetal / lead-free gunmetal

Art. no.	DN	d, ø mm	R	Product material	arc °	L cm	H cm	Z cm
63892	10	12	3/8	Gunmetal	90	3	2.5	1.3
63893	10 / 15	12	1/2	Gunmetal	90	3.2	3.1	1.5
63894	12 / 10	15	3/8	Gunmetal	90	3.2	2.7	1.2
63873	12 / 15	15	1/2	Lead-free gunmetal	90	3.5	3.1	1.5
63884	15	18	1/2	Gunmetal	90	3.5	3.4	1.5

<i>Art. no.</i>	<i>DN</i>	<i>d_ø mm</i>	<i>R_s</i>	<i>Product material</i>	<i>arc °</i>	<i>L cm</i>	<i>H cm</i>	<i>Z cm</i>
63895	15 / 20	18	3/4	Lead-free gunmetal	90	3.8	3.3	1.8
63885	20	22	3/4	Gunmetal	90	4.8	4.4	2.7
63886	25	28	1	Gunmetal	90	5.8	5.3	3.5
63887	32	35	1 1/4	Lead-free gunmetal	90	5.5	4.7	2.9
63888	40	42	1 1/2	Gunmetal	90	6.2	5.1	3.2
63889	50	54	2	Gunmetal	90	7	6.3	3.5