



DMZ

TORQUE WRENCH DREMASTER® Z 20-850 N-m / 15-630 lbf-ft

Use:


- Controlled screw tightening in the most common range of 20 - 850 N-m / 15 - 630 lbf-ft (guide for screws M7-10.9 to M24-8.8, M30-5.6)
- Adjustable, releasing and sturdy tubular torque wrench with spigot end for industry and the trades

Features:

- Classified to DIN EN ISO 6789:2003 Type II Class A, with a factory certificate allowing for operations to be traced back. Calibrated to a permitted +/- 3% deviation and better. The specifications of the standard (+/- 4%) are exceeded.
- For controlled bi-directional tightening
- Sturdy, satin chrome-plated tubular steel construction, with phosphated spigot end (16 mm or 22 mm) and high-grade plastic parts
- Ergonomically shaped, 2-component plastic grip with calibration aid
- Change-over between N-m main scale and lbf-ft ancillary scale to avoid reading errors when setting the torque wanted.
- With micrometre scale for main N-m scale for setting interim values
- Release system triggers a tactile and audible signal
- Ergonomic system for torque adjustment with reference symbol
- Provision for rapid setting with hexagon allen key, not included
- Secured adjusting/setting system
- Factory depth gauge: 32 mm (16 mm) or 56 mm (22 mm)
- Operation only with end fittings with standardised depth gauge - otherwise inaccuracies may arise.
- Depending on the application, access is possible from the front (e.g. open-end fitting) or side (e.g. reversible ratchet and socket)
- Patent applied

16

22

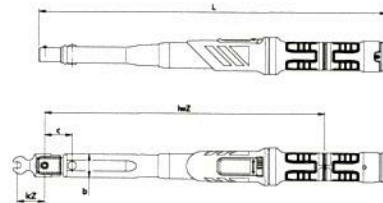

| Ø | N-m | lbf-ft | Scale | scale ring | L | lwZ | lcZ | b | c | Weight | Code | No. |
|----|---------|---------|--------|------------|---------|---------|-----|------|-----|--------|---------|---------|
| 16 | 20-100 | 15-75 | 5 N-m | 0,5 N-m | 405.5 | 326.2 | 32 | 27.5 | 32 | 0.900 | 2641518 | DMZ 100 |
| 16 | 40-200 | 30-150 | 10 N-m | 1 N-m | 496.5 | 417.2 | 32 | 27.5 | 32 | 1.100 | 2641526 | DMZ 200 |
| 16 | 60-300 | 45-220 | 10 N-m | 1 N-m | 587.5 | 508.2 | 32 | 27.5 | 32 | 1.300 | 2641534 | DMZ 300 |
| 16 | 80-400 | 60-300 | 10 N-m | 1 N-m | 677.5 | 598.2 | 32 | 33.0 | 32 | 2.200 | 2641542 | DMZ 400 |
| 22 | 110-550 | 80-405 | 10 N-m | 1 N-m | 913.0 | 840.7 | 56 | 36.5 | 37 | 3.600 | 2641550 | DMZ 550 |
| 22 | 150-750 | 110-550 | 10 N-m | 1 N-m | 1,194.0 | 1,121.7 | 56 | 38.5 | 318 | 4.700 | 2641569 | DMZ 750 |
| 22 | 250-850 | 185-630 | 10 N-m | 1 N-m | 1,341.0 | 1,268.7 | 56 | 38.5 | 465 | 5.000 | 2641577 | DMZ 850 |

GDMZ

TORQUE WRENCH SET DREMASTER® Z

- The DREMASTER® DMZ as a practical tool set
- Most-widely-used tools in a robust sheet-metal case
- Clearly organised - everything always easily accessible
- With foam-material inlay modules (on request, these can be customised or extended individually)

16



| Ø | N-m | lbf-ft | Contents | Weight | Code | No. |
|----|--------|--------|---|--------|---------|----------|
| 16 | 20-100 | 15-75 | No. DMZ 100 in sheet-metal case | 4.5 | 2641704 | GDMZ 100 |
| 16 | 40-200 | 30-150 | 17 19 24 ratchet head, 17 19 24 and 1/2" ratchet head | 5.8 | 2641712 | GDMZ 200 |
| 16 | 60-300 | 45-220 | 17 19 24 ratchet head, 17 19 24 and 1/2" ratchet head | 6.5 | 2641720 | GDMZ 300 |
| 16 | 80-400 | 60-300 | 24 27 30 32 ratchet head, 24 27 and 1/2" ratchet head | 7.2 | 2641728 | GDMZ 400 |