


# 280

Hexagon nipple

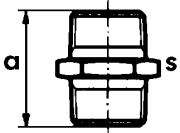


ISO N8

Dimension	Code	a	s
• S 1/8 □	770 280 101	29	17
• V 1/8 □	770 280 201		
• S 1/4 □	770 280 102	36	19
• V 1/4 □	770 280 202		
• S 3/8	770 280 103	38	22
• V 3/8	770 280 203		
• S 1/2	770 280 104	44	28
• V 1/2	770 280 204		
• S 3/4	770 280 105	47	32
• V 3/4	770 280 205		
• S 1	770 280 106	53	42
• V 1	770 280 206		
• S 1 1/4	770 280 107	57	50
• V 1 1/4	770 280 207		
• S 1 1/2	770 280 108	59	55
• V 1 1/2	770 280 208		
• S 2	770 280 109	68	70
• V 2	770 280 209		
• S 2 1/2	770 280 110	75	85
• V 2 1/2	770 280 210		
• S 3	770 280 111	83	100
• V 3	770 280 211		
• S 4	770 280 112	95	131
• V 4	770 280 212		

# 281

R-L  
Hexagon nipple with right- and left-hand thread

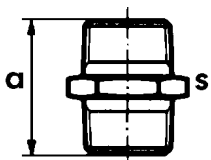

ISO N8

Dimension	Code	a	s
S 3/8 ▲	770 281 103	38	22
V 3/8	770 281 203		
• S 1/2	770 281 104	44	28
• V 1/2	770 281 204		
• S 3/4	770 281 105	47	33
• V 3/4	770 281 205		
• S 1	770 281 106	53	42
• V 1	770 281 206		
S 1 1/4	770 281 107	57	50
V 1 1/4	770 281 207		
S 1 1/2	770 281 108	59	55
V 1 1/2	770 281 208		
S 2	770 281 109	68	70
V 2	770 281 209		