


WATER OPEN HOSE REELS / STEEL

DVO series - Steel with PVC hose



Part number	Length (m)	Temperature min/max (°C)	Max. operating pressure (bar)	Net weight (Kg)	Profile
DVO 1320LS	20.00	-15.00 / 60.00	10.00	19,5	WATER
DVO 1515LS	15.00	-15.00 / 60.00	10.00	18	WATER

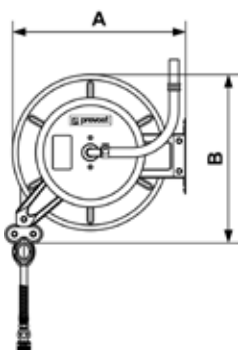

Part number	Dim. A (mm)	Dim. B (mm)	Ø int/ext (mm)
DVO 1320LS	495.00	475.00	12.70 / 17.00
DVO 1515LS	495.00	475.00	15.00 / 21.00