


KEMET Part Number: FX5(75)-120X120T2900
(UFSFX57R5HT290)

KEMET, FX5, Flex Suppressors, Noise Suppression

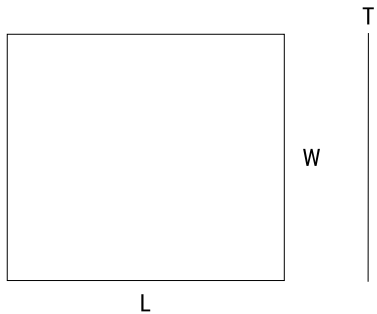

General Information	
Series:	FX5
Style:	Sheet
Description:	Flex Suppressor High Permeability Type
Features:	High Permeability Type
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
Sheet Size	120x120mm
L	120mm NOM
W	120mm NOM
T	0.075mm NOM

Specifications	
Temperature Range:	-40/+105C
Magnetic Permeability:	150 u At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.3 Atm TYP

Packaging Specifications	
Weight:	5.12 g