

- Replacement for PAR16 high voltage 50 W Halogen lamp
- High colour rendering index at $\geq Ra95$
- Up to 85% energy saving
- Dimmable
- Lifetime of 25,000 hrs
- For accent lighting; ideal for spotlighting of various objects in shops, museums, restaurants or along the corridor



Order Code 52041

General Data

Lamp Socket GU10
Design Lens

Geometric Data

Length (mm) 81.7
Diameter (mm) 50
Weight (g) 139


Electric Data

Wattage (W) 8.5
Voltage (V) 220-240
Power Factor ≥ 0.85
Operating Frequency (Hz) 50-60 Hz

Photometric Data

Luminous Flux (lm) 310
CRI ≥ 95
CCT 2700 K –warm white
Luminous Intensity (cd) 720
Beam Angle (°) 30°
Lifetime 25,000 hrs

Equivalent to (W) 50 W

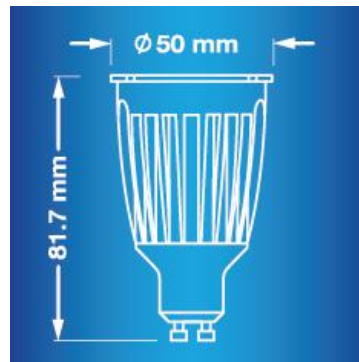



Order Code 52041

Product Description LED PAR16 GU10 8.5W 2700K WW 310LM DIM

Technical Packaging Details

Barcode	023942520412
EAN 128	(02)00023942520412(37)20(91)53
EAN 14	50023942520417
Pack Dimensions (HxWxL)	107 mm x 66 mm x 66 mm
Pack Weight	TBC
Carton Qty (Shipping Unit)	10
Carton Dimensions (HxWxL)	145 mm x 556 mm x 318 mm
Cartons/Layer	9
Layers/Pallet	5
Units/Pallet	900

Photometric Diagram

52041

