


## Datasheet

### Pointed 2-part spring probe

RS Stock number [261-5137](#)

Dimensions: (mm)

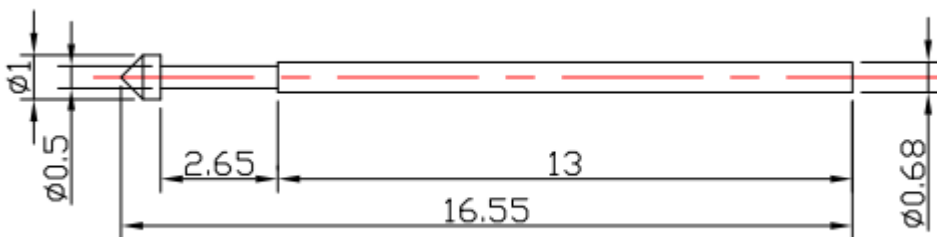

## Specifications

- Plunger: SK4 Rh Plated 4 $\mu$ "
- Spring: SWP Au Plated
- Barrel: PhBz Au Plated Flash
  - (min center) : 1.27mm [0.05]
  - (full stroke): 3.35mm [0.1319]
  - 2.65mm [0.1043]
- Full Stroke Spring Force: + 20% 100g [3.54oz]
- 2/3 Stroke Spring Force: + 20% 65g [2.30oz]
- Current Rating: 1.5A
- Contact Resistance: 70m  $\Omega$
- Recommended Hole Size: R-OV- 0.90mm [0.0354]  
R-OV- 0.95mm [ 0.0374]