


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1722583110](#)  
**Status:** **Active**  
**Overview:** [Ultra-Fit Power Connectors](#)  
**Description:** Ultra-Fit Tangless Receptacle Housing, 3.50mm Pitch, Dual Row, 10 Circuits, Black, Glow-Wire Capable

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification 1723230004-000 (PDF)</a>
<a href="#">Product Specification 1723230001-TS-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-172323-0001-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>
<a href="#">Application Specification 1723230003-000 (PDF)</a>	

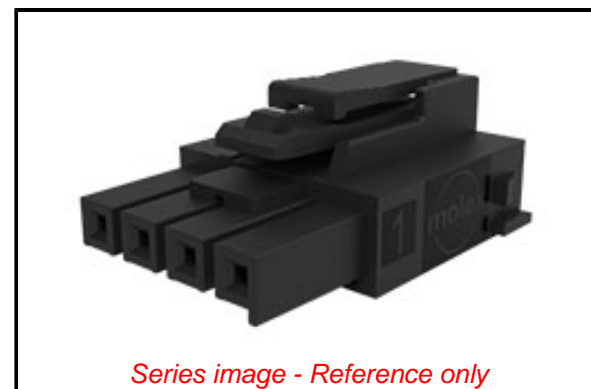

**General**

Product Family	Crimp Housings
Series	<a href="#">172258</a>
Application	Power, Wire-to-Board
Overview	<a href="#">Ultra-Fit Power Connectors</a>
Product Literature Order No	987651-1008
Product Name	Ultra-Fit
UPC	191128805230

**Physical**

Circuits (maximum)	10
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2.839/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.50mm
Pitch - Termination Interface	3.50mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

**Material Info**

**Reference - Drawing Numbers**

Application Specification	1723230003-000
Packaging Specification	1723230004-000
Product Specification	1723230001-TS-000, PS-172323-0001-001
Sales Drawing	1722580003-000

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[172258](#) Series

**Mates With**

Ultra-Fit Right-Angle Header [172316](#)  
<br>Ultra-Fit Vertical Header [172298](#) ,  
[172299](#)

**Use With**

Ultra-Fit Tangless Female Crimp Terminal  
[172253](#) <br>Ultra-Fit Tangless TPA Retainer  
[172264](#)