

USB Flash Drives

TransMemory™ U363





A USB with a feeling of quality

128 GB 64 GB 32 GB

Color 


Worry less about leaving it behind. Attach it easily to your house or car keys. Functionality is balanced with sleek design & a read speed of 120MB/s.



-  High quality metal body design
-  Up to 128 GB capacity
-  Read speed up to 120MB/s
-  Use for: PC & MAC, tablets, TVs



Product Specifications

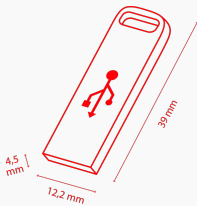

Capacity	32 GB, 64 GB, 128 GB	Dimensions	39 mm (L) x 12.2 mm (W) x 4.5 mm (H)
Colours	Metallic	Weight	Approx. 6g
Interface	Super Speed USB 3.0 and Hi-Speed USB 2.0	Operating Temperature	0° to +40°C (Recommended)
Power Supply	Bus powered from USB port.	Storage Temperature	-20° to +60°C (Recommended)
Compatible PC Models	Models equipped with the following OS, and the Type-A USB interface as a standard feature: OS X v10.6.6 - v10.11, macOS X v10.12, Windows 7, Windows 8.1, Windows 10	Warranty	5 years
Max read speed (MB/s)	Up to 120 MB/s		

Product Range

Part number	Capacity	Color	EAN
THN-U363S0320E4(TU)	32 GB	Metallic	4047999400301
THN-U363S0640E4(TU)	64 GB	Metallic	4047999400318
THN-U363S1280E4(TU)	128 GB	Metallic	4047999400325

Contact

Toshiba Memory Europe GmbH

Hansaallee 181
40549 Düsseldorf
Germany