


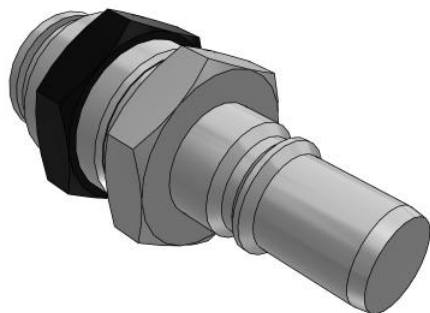

## KK\*P-\*E, S-Couplers, Bulkhead Type with One-touch Fitting KK4P-10E

Datasheet




### General series information

- Bulkhead Type with One-touch Fitting.
- Body size: M5, 1/8, 1/4, 1/2.
- Applicable Tubing O.D.: ø3.2, ø4, ø6, ø8, ø10, ø12, ø16.

### Standard specifications

|                             |                                                                               |
|-----------------------------|-------------------------------------------------------------------------------|
| Body Size                   | 4 (1/4)                                                                       |
| Applicable Tubing O.D.      | Ø10 mm                                                                        |
| Pressure medium             | Air, Water                                                                    |
| Maximum operating pressure  | 1.0 MPa                                                                       |
| Minimum operating pressure  | 0 kPa                                                                         |
| Proof pressure              | 1.5 MPa                                                                       |
| Maximum ambient temperature | 60 °C / 40 °C for Water                                                       |
| Minimum ambient temperature | -5 °C (with no freezing) / 5 °C for Water                                     |
| Effective Area              | 39 mm <sup>2</sup>                                                            |
| Sealing principle           | Electroless nickel plated (copper-free application), With male thread sealant |
| Weight                      | 0.062 Kg                                                                      |

## Dimensions

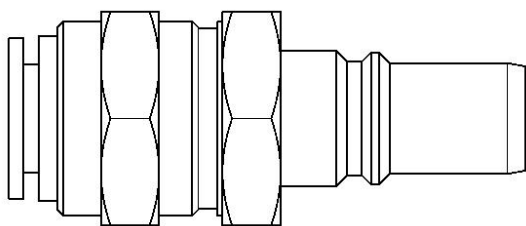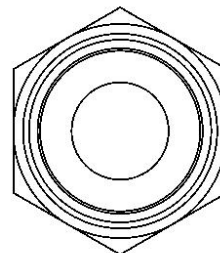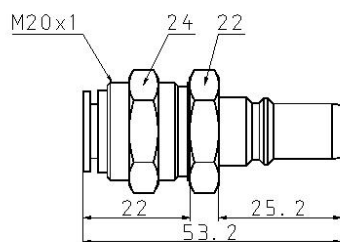

## Additional information

Catalogue

[KK-C\\_EU.pdf](#)