

 
 
 
SINGLE WHITE DOB

IP20 Diffused on board flexible LED tape




Product Features

- Uniform light output across the entire length
- Industrial grade adhesive backing tape
- Compatible with all dimming types
- Bespoke design and cutting service available
- IoT ready when paired with suitable controller
- Longer lengths available upon request
- 3 years warranty



Specifications

Stock Code	0187-621	0969-337	0347-481	1016-547	1564-946
Part Code	B5-DOB-24-528-F8-20	C0-DOB-24-528-F8-20	D0-DOB-24-528-F8-20	E0-DOB-24-528-F8-20	F0-DOB-24-528-F8-20
Voltage	24VDC	24VDC	24VDC	24VDC	24VDC
Power	10W/m	10W/m	10W/m	10W/m	10W/m
Lumen Output	970lm/m	970lm/m	1050lm/m	1050lm/m	1050lm/m
Efficacy	97lm/W	97lm/W	105lm/W	105lm/W	105lm/W
Colour Temp.	2500K	3000K	4000K	5000K	6000K
LED/metre	528	528	528	528	528
Cut Points	45.45mm	45.45mm	45.45mm	45.45mm	45.45mm
CRI (Ra)	>80	>80	>80	>80	>80
IP Rating	IP20	IP20	IP20	IP20	IP20
Dimensions	5000 x 8 x 1.6mm	5000 x 8 x 1.6mm	5000 x 8 x 1.6mm	5000 x 8 x 1.6mm	5000 x 8 x 1.6mm

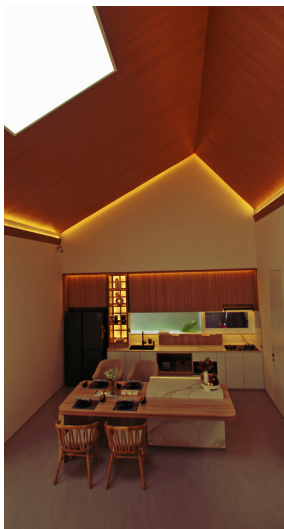

2500K




3000K



4000K



5000K

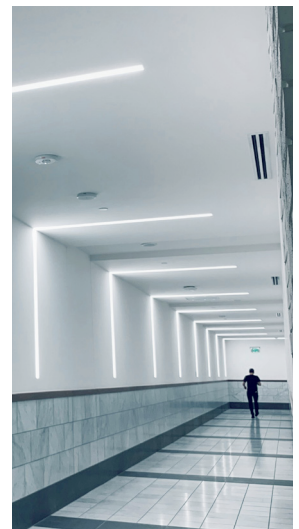


6000K




SINGLE WHITE DOB

IP67 Diffused on board flexible LED tape

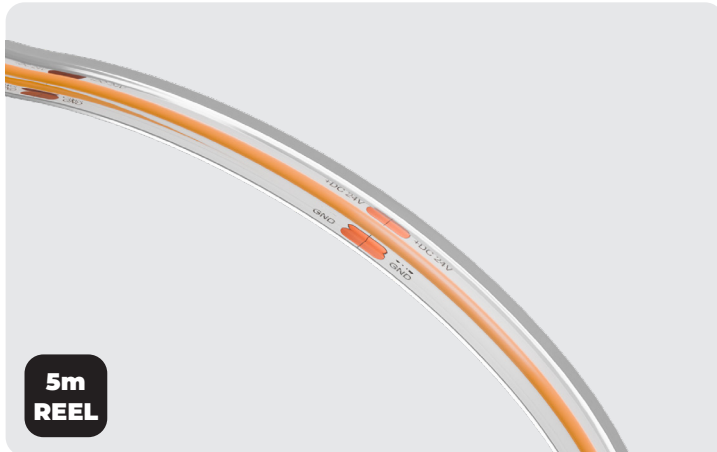

Product Features

 - Uniform light output across the entire length
- Industrial grade adhesive backing tape
- Compatible with all dimming types
- Bespoke design and cutting service available
- IoT ready when paired with suitable controller
- Longer lengths available upon request
- 3 years warranty



Specifications

Stock Code	1110-951 	0409-269 	0400-409 	1474-974 	1105-981 
Part Code	B5-DOB-24-528-F8-65	C0-DOB-24-528-F8-65	D0-DOB-24-528-F8-65	E0-DOB-24-528-F8-65	F0-DOB-24-528-F8-65
Voltage	24VDC	24VDC	24VDC	24VDC	24VDC
Power	10W/m	10W/m	10W/m	10W/m	10W/m
Lumen Output	970lm/m	970lm/m	1050lm/m	1050lm/m	1050lm/m
Efficacy	97lm/W	97lm/W	105lm/W	105lm/W	105lm/W
Colour Temp.	2500K	3000K	4000K	5000K	6000K
LED/metre	528	528	528	528	528
Cut Points	45.45mm	45.45mm	45.45mm	45.45mm	45.45mm
CRI (Ra)	>80	>80	>80	>80	>80
IP Rating	IP67	IP67	IP67	IP67	IP67
Dimensions	5000 x 10 x 4mm	5000 x 10 x 4mm	5000 x 10 x 4mm	5000 x 10 x 4mm	5000 x 10 x 4mm



2500K



3000K



4000K



5000K



6000K




SINGLE WHITE DOB

IP20 & IP67 Diffused on board flexible LED tape



Compatibility*

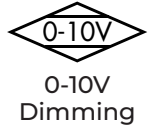

Control Methods (sold separately)

- Remote Control - SCD107W (receiver included)
- Bluetooth (Apps, Voice Control) - BLE-15A-REV-A
- Mains dimming options available using UVC24XXTD LED driver range

Suggested Drivers

Up to 3m

Power supplied from ONE end

PCV2436-REV-A
(IP20)

PCV2436E-REV-A
(IP67)

Up to 5m

Power supplied from ONE end

PCV2450-REV-A
(IP20)

PCV2475E-REV-A
(IP67)

Up to 10m


Power supplied from MIDDLE

PCV24101-REV-A
(IP20)


PCV24100E-REV-A
(IP67)

Mechanical Diagram

IP20

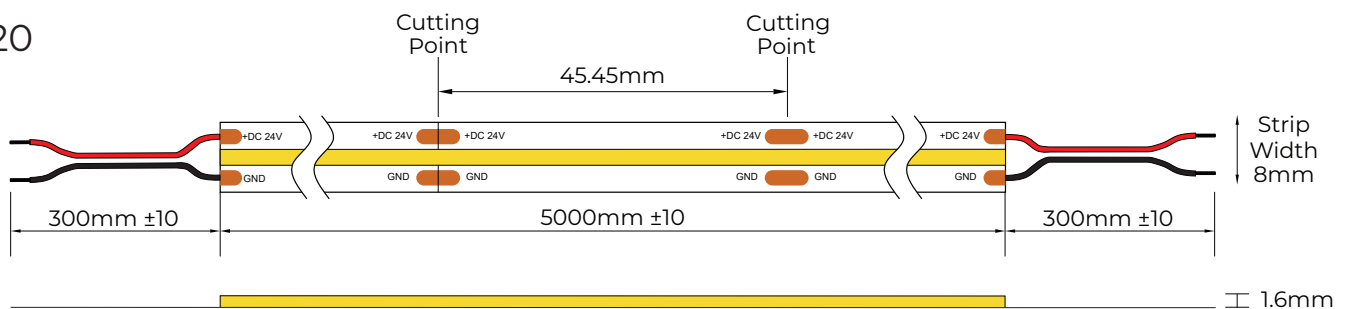

IP67

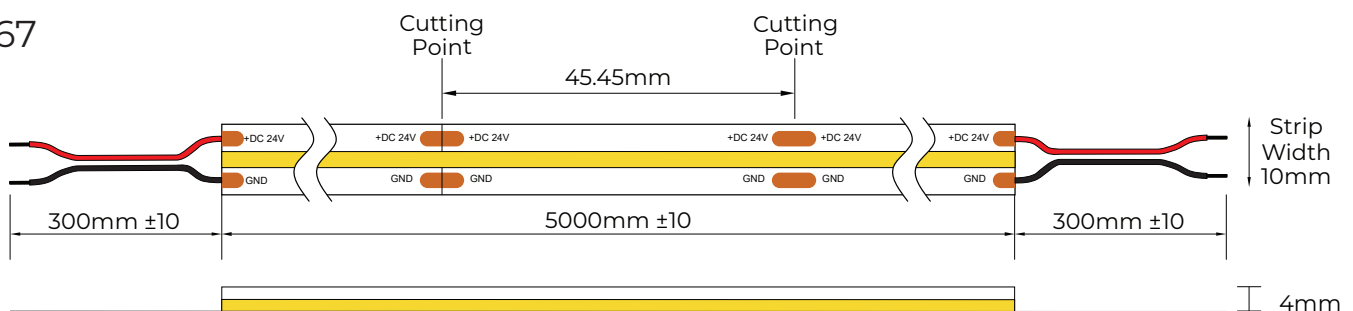

* Product compatibility with other brands is shown for informational purposes only. All third-party company names and logos are trademarks of their respective owners and do not constitute an endorsement or partnership with our company.