


SPECIFICATION:

Material	Nylon
Protection rating	IP 68
Temperature range	-40...+100 °C

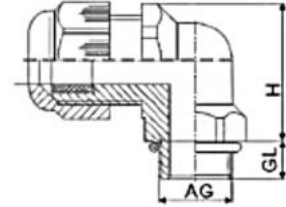

PRODUCT RANGE:

Art. Nr.	Thread	Clamping range	Colour	GL	H	AG	Spanner size	Panel mounting hole
RND 465-00863	PG11	5...10 mm	Grey	8 mm	39 mm	18.6 mm	22 mm	18.6-18.9 mm
RND 465-00864	PG13.5	6...12 mm	Grey	9 mm	43 mm	20.4 mm	24 mm	20.4-20.7 mm
RND 465-00865	PG16	10...14 mm	Grey	10 mm	48 mm	22.5 mm	27 mm	22.5-22.8 mm
RND 465-00866	PG21	13...18 mm	Grey	11 mm	56 mm	28.3 mm	33 mm	28.3-28.6 mm
RND 465-00867	PG11	5...10 mm	Black	8 mm	39 mm	18.6 mm	22 mm	18.6-18.9 mm
RND 465-00868	PG13.5	6...12 mm	Black	9 mm	43 mm	20.4 mm	24 mm	20.4-20.7 mm
RND 465-00869	PG16	10...14 mm	Black	10 mm	48 mm	22.5 mm	27 mm	22.5-22.8 mm
RND 465-00870	PG21	13...18 mm	Black	11 mm	56 mm	28.3 mm	33 mm	28.3-28.6 mm
RND 465-00871	M16 x 1.5	4...8 amm	Grey	8 mm	24 mm	16 mm	19 mm	16-16.3 mm
RND 465-00872	M18 x 1.5	5...10 mm	Grey	8 mm	39 mm	18 mm	22 mm	18-18.3 mm
RND 465-00873	M20 x 1.5	6...12 mm	Grey	9 mm	43 mm	20 mm	24 mm	20-20.3 mm
RND 465-00874	M22 x 1.5	10...14 mm	Grey	10 mm	48 mm	22 mm	27 mm	22-22.3 mm
RND 465-00875	M25 x 1.5	13...18 mm	Grey	11 mm	56 mm	25 mm	33 mm	25-25.3 mm
RND 465-00876	M32 x 1.5	18...25 mm	Grey	11 mm	68 mm	32 mm	41/42 mm	32-32.3 mm
RND 465-00877	M16 x 1.5	4...8 amm	Black	8 mm	24 mm	16 mm	19 mm	16-16.3 mm
RND 465-00878	M18 x 1.5	5...10 mm	Black	8 mm	39 mm	18 mm	22 mm	18-18.3 mm
RND 465-00879	M20 x 1.5	6...12 mm	Black	9 mm	43 mm	20 mm	24 mm	20-20.3 mm
RND 465-00880	M22 x 1.5	10...14 mm	Black	10 mm	48 mm	22 mm	27 mm	22-22.3 mm
RND 465-00881	M25 x 1.5	13...18 mm	Black	11 mm	56 mm	25 mm	33 mm	25-25.3 mm
RND 465-00882	M32 x 1.5	18...25 mm	Black	11 mm	68 mm	32 mm	41/42 mm	32-32.3 mm