

Frame Han 24HPR EasyCon Short PE-Mod-a-h

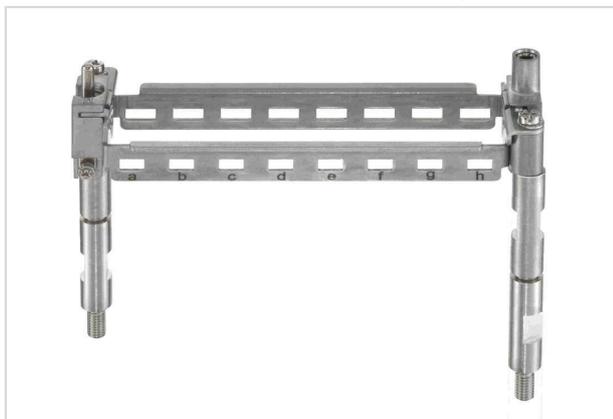


Image is for illustration purposes only. Please refer to product description.

Part number	09 40 024 9936
Specification	Frame Han 24HPR EasyCon Short PE-Mod-a-h
HARTING eCatalogue	https://harting.com/09400249936

Identification

Category	Accessories
Series of hoods/housings	Han [®] HPR EasyCon
Type of accessory	Frame
Description of the accessory	for up to 8 single modules
	a ... h
	Low construction

Version

Size	24 B
Details	ATTENTION! Only to be used with Han [®] 24 HPR EasyCon Short hoods and housings!
Pack contents	1x male PE adapter
	1x female PE adapter
	2x M4/M5 distance bolts (AF 7)
	2x M5/M6 distance bolts (AF 7)
	2x M3 screw
	2x M4 screw
	2x washer SK S4

Technical characteristics

Conductor cross-section	4 ... 10 mm ² PE terminal power side
	1 ... 2.5 mm ² PE terminal signal side
Tightening torque	0.5 Nm Fixing screws M3
	1.5 Nm Fixing screws M4
	6 Nm Distance bolt
	0.8 Nm PE terminal clamp 1 ... 2.5 mm ²
	1.5 Nm PE terminal clamp 4 ... 10 mm ²
Limiting temperature	-40 ... +125 °C



Pushing Performance
Since 1945

Technical characteristics

Mating cycles ≥ 500

Material properties

Material (accessories)	Zinc die-cast Stainless steel
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead

Commercial data

Packaging size	1
Net weight	0.01 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140194489
eCl@ss	27440210 Fixing element for industrial connectors
ETIM	EC002310
UNSPSC 24.0	39121466