
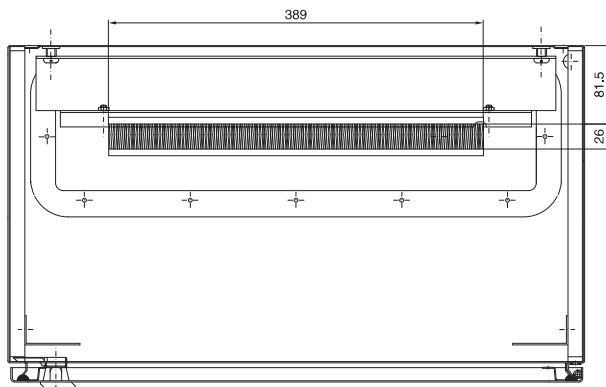
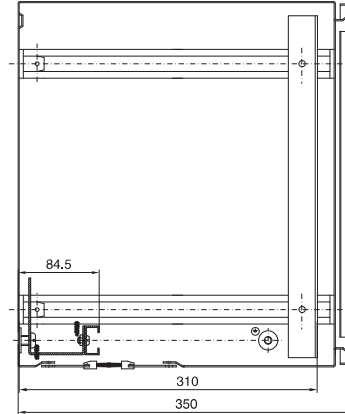


# Enclosures

## Wall-mounted network enclosures

### Wall-mounted enclosures AE

With 482.6 mm (19") mounting angles Catalogue 33, page 67

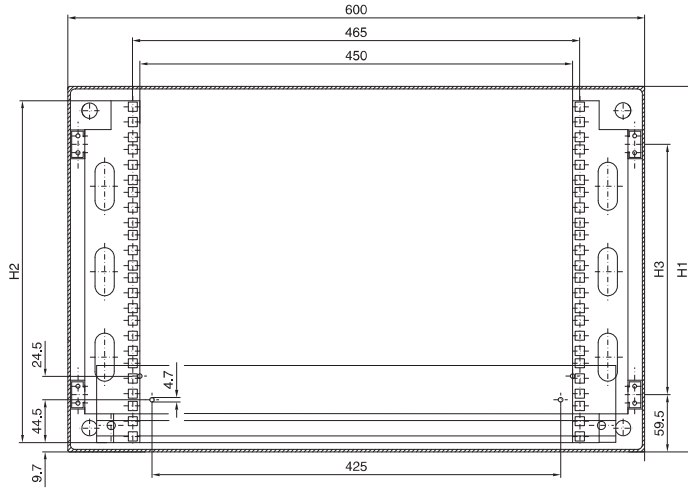


Model No. DK	U	Height dimensions mm		
		H1	H2	H3
7641.000	8	380	355	261
7643.000	13	600	578	481
7645.000	16	760	711	641


## Wall-mounted network enclosures

### Wall-mounted enclosures AE

With 482.6 mm (19") pull-out frame Catalogue 33, page 68

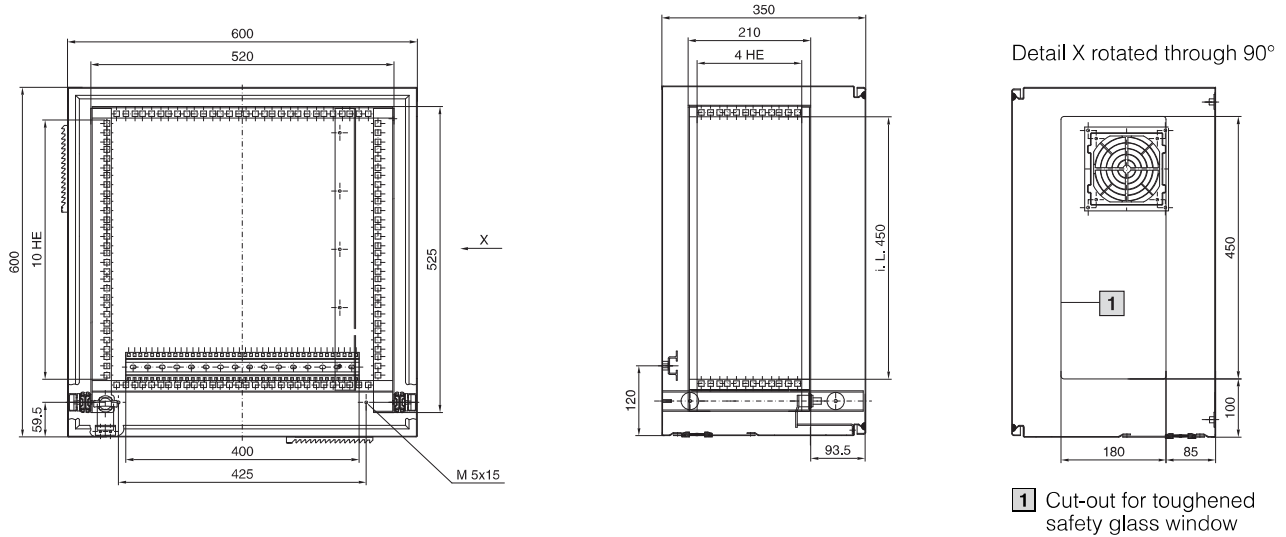


1 Cut-out for toughened safety glass window

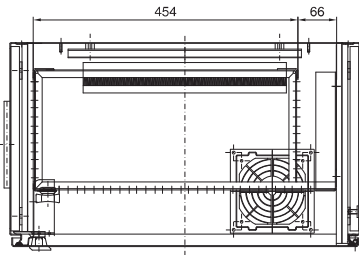

Model No. DK	U (HE)		Width mm	Height mm	Depth mm
	vertical	horizontal			
7644.000	4	10	600	600	350

### Small fibre-optic distributors

Catalogue 33, page 69

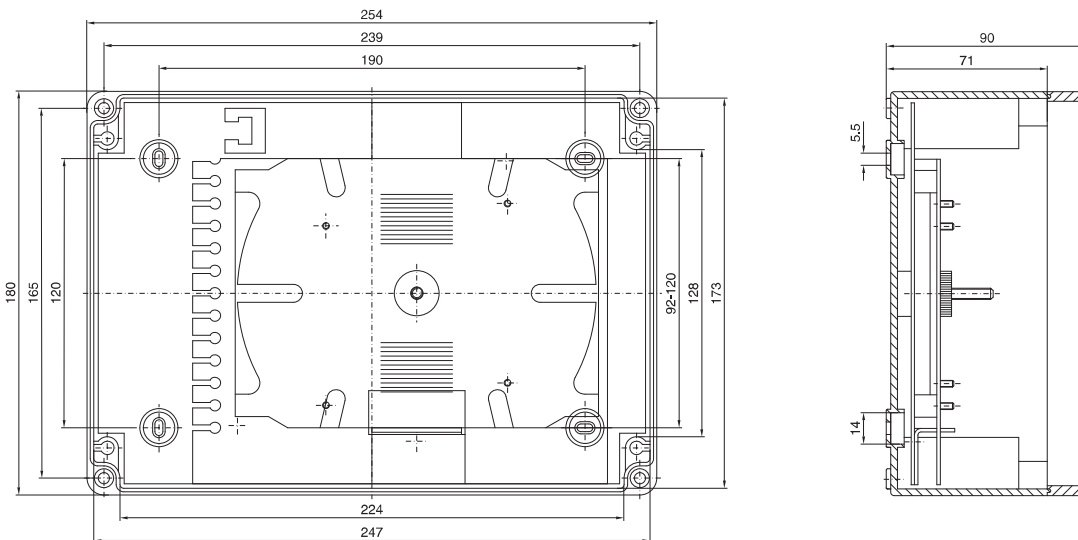

Model No. DK	Fibres	Width mm	Height mm	Depth mm
7451.000	1 - 24	180	254	90