



1750
LUMEN



4 1/2 - 195H
RUNTIME



50M
RANGE



IPX5
IP RATING



USB
TYPE-C


SLR-1750 - WORK LIGHT WITH POWERBANK

- 1750 Lumen white COB LED, 6500k
- USB powerbank function
- Red LED modes for emergency / signalling / night vision
- Super tough copolymer & aluminium construction
- Glow-in-the-dark strip around reflector for extra visibility
- 180° Adjustable handle/stand/hook
- Strong magnets within base
- Spring loaded carabiner hook on the base
- 1m high quality USB Type-C charging cable (included)
- 3A USB Type-C charging - 7 hours charge time
- Upgraded 'LG' batteries for greater longevity

BATTERY 3.7v 10400mAh Li-ion Rechargeable Battery

WEIGHT 600g

DIMENSION folded - 158 x 102 x 55mm / extended - 268 x 102 x 48mm

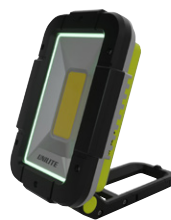

GLOW-IN-THE-DARK STRIP



BATTERY LEVEL INDICATORS